


Grey Thermoplastic Rubber Trolley Wheel 160mm, 170kg

Thermoplastic rubber-tyred wheel

PRODUCT

Article number

325-501-160L20

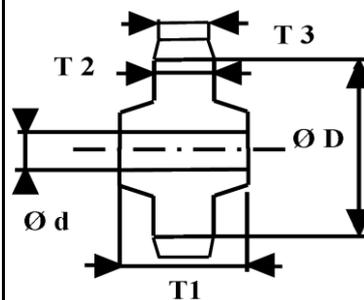

Product Details

Wheel Rim : made of grey impact-resistant polypropylene.
Tread : grey thermoplastic rubber, integrated type. Non-marking.
Hub : symmetrical with plain bore.

Specifications

Wheel Diameter - ØD ± 1%	160 mm
Hub Type	Plain
Hub Length T1	58 mm ±1
Width of Tread T2	38 mm ±1
Width of Tread-on floor T3	38 mm ±1
Axle Hole Ø d	Ø 20 mm
Hardness of tread A ±3	A 87° Shore
Load capacity	170 Kg
Temperature	-10 / +50 °C
Weight	0,3 Kg

TECHNICAL DATA

Applications :

Quiet and non-marking materials handling.
Lightweight, low starting effort.
Suitable for all interiors floors (warehouses, offices, shops, kitchens,...).