

Bocube

Enclosures, polycarbonate UL 94 V0, crystal-clear lid



B 180809 PC-V0-G 7035

Order no.: 96024135

* = Available on request.

Characteristics

Colour of enclosure group

Light grey, similar to RAL 7035

Colour of enclosure group

Light grey

Protection class

IP 66, 68 - 1,2m (2 hours)

Enclosure Material

ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C)


PU seal, foamed; for details please see Technical Information

Dimensions

Dimensions

191 x 80 x 90 mm

Product drawing

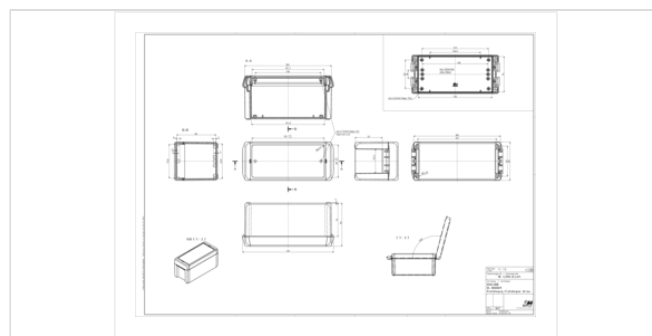

Scope of delivery

Lid and base, hinged quick-release catches

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

Technical documentation / Downloads

Technical drawings

3D product data in STEP format: Registration necessary

Product drawing in PDF format: 96024135 B-180809-PC-V0-G-7035.pdf (229.3 KB)

Product information

Bocube GB.pdf (1.9 MB)

Highlights Bocube.pdf (3.8 MB)

Product drawing in DXF format: 96024135 B-180809-PC-V0-G-7035.dxf (3.8 MB)

Drawing for mechanical processing: 96024135 B-180809-PC-V0-G-7035-G.dxf (2.9 MB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

Works Test Certificates

688 WPZ-Bocube-PC-V0 DE.pdf (184.6 KB)

689 WPZ-Bocube-ABS DE.pdf (165.1 KB)

689 WPZ-Bocube-ABS EN.pdf (160.3 KB)

688 WPZ-Bocube-PC-V0 EN.pdf (179.1 KB)

Matching accessories



Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS

96310100	B SC 08 PC-V0 3000	For B 0808.., B 1008.., B 1408.., B 1808..	Flame red
96310102	B SC 08 PC-V0 5002	For B 0808.., B 1008.., B 1408.., B 1808..	Ultramarine blue
96310109	B SC 08 PC-V0 6029	For B 0808.., B 1008.., B 1408.., B 1808..	Mint green
96310104	B SC 08 PC-V0 7024	For B 0808.., B 1008.., B 1408.., B 1808..	Graphite grey
96310105	B SC 08 PC-V0 7035	For B 0808.., B 1008.., B 1408.., B 1808..	Light grey
96310103	B SC 08 PC-V0 1023	For B 0808.., B 1008.., B 1408.., B 1808..	Traffic yellow



Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

96910100	B SC HB 08 PC-V0 3000	For B 0808.., B 1008.., B 1408.., B 1808..	Flame red
96910102	B SC HB 08 PC-V0 5002	For B 0808.., B 1008.., B 1408.., B 1808..	Ultramarine blue
96910109	B SC HB 08 PC-V0 6029	For B 0808.., B 1008.., B 1408.., B 1808..	Mint green
96910104*	B SC HB 08 PC-V0 7024	For B 0808.., B 1008.., B 1408.., B 1808..	Graphite grey
96910105*	B SC HB 08 PC-V0 7035	For B 0808.., B 1008.., B 1408.., B 1808..	Light grey
96910103	B SC HB 08 PC-V0 1023	For B 0808.., B 1008.., B 1408.., B 1808..	Traffic yellow



Wall brackets

96510005	B WL 7035	For B 08... - B 26...	Light grey
96510004	B WL 7024	For B 08... - B 26...	Graphite grey



Mounting panels, laminated paper, 2 mm

96604100	B M 1808	For B 1808..
----------	----------	--------------



Front panels, 2 mm, natural-coloured anodised aluminium

96704100 B FP 1808 For B 1808.., front panel thickness 2.0 mm



Sets of screws

96300000 B SHR D (for optional screwing of enclosures B 0808 - 2617)
 96600010 B M-SHR C (for fixing mounting panels B M 1008-2736)
 96700000 B FP-SHR A (for fixing front panels)



Distance bolts

96756000 DIBLZ AK 30x7/IM3/56 ND = 2.4-2.6, for B....09 if a mounting plate is used
 96758000 DIBLZ AK 30x5/IM3/58 ND = 2.4 - 2.6, for B....09



Blanking plugs to determine the hinge side

96410000 B VS 3000 Flame red
 96410005 B VS 7035 Light grey
 96410004 B VS 7024 Graphite grey



DIN rail acc. to DIN EN 60715 TH 15

22151501 TS 15 For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



DIN rail acc. to DIN EN 60715 G 32

22321501 TS 32 For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



DIN rail acc. to DIN EN 60715 TH 35

22351501 TS 35 For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



Pressure compensation membrane DAE

52011000 DAE-D11 Self-adhesive membrane ø 11 mm