

## OT DIM

### OPTOTRONIC OT DIM | Dimmers for LED modules



#### Product benefits

- Intelligent electronic constant-voltage 1-channel 1...10 V dimmer

#### Product features

- Maximum operating output voltage: 5 A
- Cable clamp housing for independent mounting
- Dimming range: 0.1...100 %
- Control input is separate from the output in accordance with SELV requirements
- Reversible protection mechanisms for short-circuits, overtemperature and -loads

---

## Technical data


---

### Electrical data

System wattage	144 W
Nominal voltage	10...24 V
Output voltage	10.5...24 V
Output power	120 W

### Dimensions & weight

---

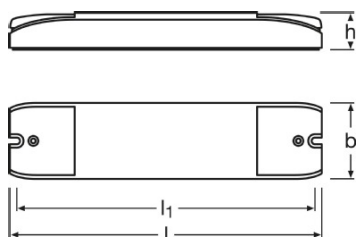

---

### Product line drawing

Length	172.0 mm
Width	42.0 mm
Height	20.0 mm

### Temperatures

Ambient temperature range	-20...+50 °C
---------------------------	--------------

### Capabilities

Dimming interface	1...10 V
Number of control outputs	1

### Certificates & standards

Type of protection	IP20
--------------------	------

---

## Download Data

---

File
------

## Product datasheet



Addon Technical Information  
ADDON TECHNICAL INFORMATION OT DIM VS20 OSRAM (GB)



Declarations of conformity  
Declaration of conformity OT Dimmer OT Sequencer

---

---

### Disclaimer

---

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.