

Features


- Potable water applications up to +23°C
- WRAS-approved for safe use with drinking water
- Suitable for general sealing and gasketing
- Excellent weather resistance, durability, and chemical resistance
- High tensile strength (9 MPa) and good compression set resistance
- Resists various chemicals commonly encountered in water and industrial applications
- Cloth/Cloth effect finish

RS PRO Black EPDM WRAS Approved Rubber Sheet

1m x 1.6m x 1.5mm

+100°C to -15°C

RS Stock No.: 0205551

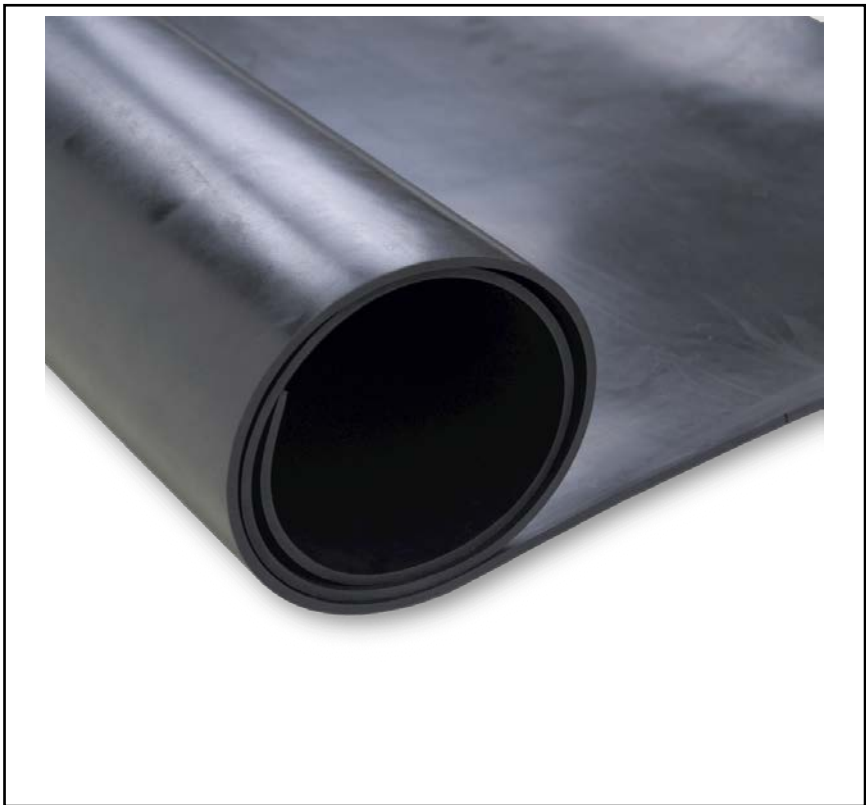

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

*The RS PRO Ethylene Polypropylene (EPDM) rubber sheet is suitable for a wide range of applications including gaskets and seals in potable water systems, food processing equipment, chemical processing equipment and roofing and construction.*

General Specifications

Colour	Black
Material	Ethylene Polypropylene (EPDM)
Adhesive Backing	No
Suitability	WRAS approved for use with potable water

Mechanical Specifications

Length	1m
Width	1.6m
Thickness	1.5mm
Elongation	450%
Tensile Strength	9 MPa
Hardness	70 ShA

Operation Environment Specifications

Maximum Operating Temperature	100°C
Minimum Operating Temperature	-15°C

Similar Products

Stock No	Adhesive Backing	Thickness
0205551	No	1.5mm
0205550	No	3mm
0205552	No	6mm