

**Protecteurs HELAVIA®**  
**en caoutchouc polychloroprène noir**  
**Caractéristiques techniques pages D100**



**HELAVIA®**




type	code article		type	code article		type	code article	
15-009	0253 0001 010	100	15-391	0253 0063 010	100	15-649	0253 0075 010	100
15-043	0253 0004 010	100	15-401	0256 0001 010	100	15-651	0253 0076 010	100
15-045	0253 0005 010	100	15-402	0256 0002 010	100	15-672	0253 0092 010	50
15-049	0253 0008 010	50	15-403	0256 0003 010	100	15-680	0253 0095 010	100
15-083	0253 0013 010	25	15-405	0256 0005 010	100	15-691**	0253 0110 010	100
15-130	0253 0014 010	50	15-410	0253 0051 010	100	15-692**	0253 0111 010	50
15-131	0253 0015 010	50	15-411	0253 0052 010	50	15-693**	0253 0112 010	50
15-147	0253 0016 010	50	15-412	0253 0053 010	50	15-721	0253 0003 010	100
15-159	0253 0017 010	100	15-538	0253 0064 010	100	15-737	0253 0080 010	50
15-164	0253 0018 010	50	15-561	0253 0065 010	100	15-747	0253 0083 010	50
15-169	0253 0019 010	100	15-579	0253 0066 010	50	15-748	0253 0084 010	50
15-170	0253 0020 010	100	15-592	0253 0070 010	50	15-751	0253 0091 010	50
15-171	0253 0021 010	100	15-596*	0253 0071 010	100	15-756	0253 0085 010	50
15-172	0253 0022 010	100	15-602**	0253 0072 010	50	15-760	0253 0113 010	100
15-190	0256 0010 010	100	15-608	0253 0073 010	100	15-781	0253 0087 010	50
15-306	0253 0057 010	100	15-625	0252 0319 010	100	15-806	0253 0114 010	100
15-318	0253 0058 010	100	15-633	0253 0077 010	50	15-821	0253 0115 010	100
15-320	0253 0059 010	25	15-642	0253 0078 010	100	15-822	0253 0117 010	100
15-329**	0253 0060 010	25	15-643	0253 0079 010	50			
15-354	0253 0061 010	100						
15-380	0253 0062 010	100						
15-383	0253 0056 010	100						


**Bride métallique de serrage pour protecteur 15-412**

**16-900** 0684 0054 000 100


\*caoutchouc Nitrile - \*\*caoutchouc EPDM

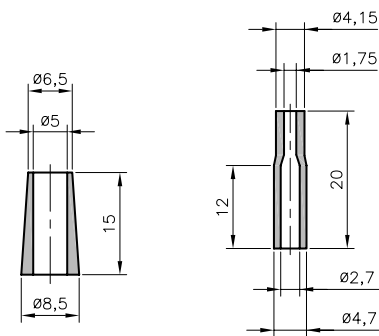


**15-009**  
0253 0001 010

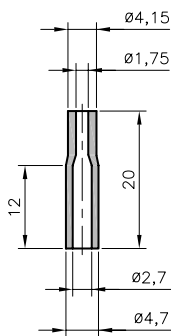


**15-190**  
0256 0010 010

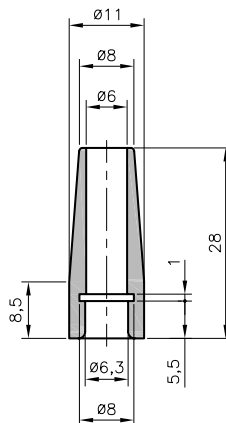


**15-318**  
0253 0058 010

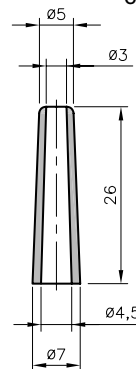


**15-401**  
0256 0001 010

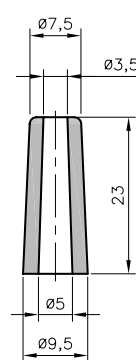


**15-402**  
0256 0002 010

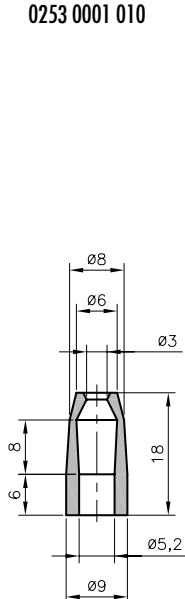


**15-403**  
0256 0003 010

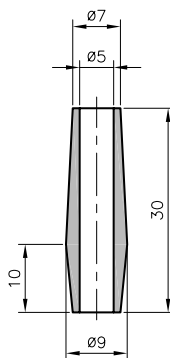


**15-405**  
0256 0005 010

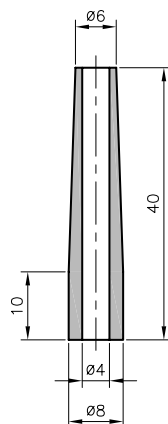


**15-680**  
0253 0095 010

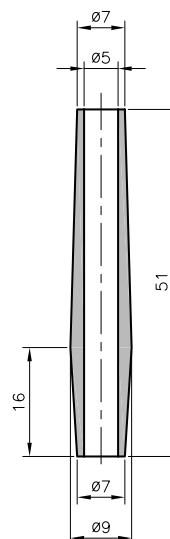


**15-043**  
0253 0004 010

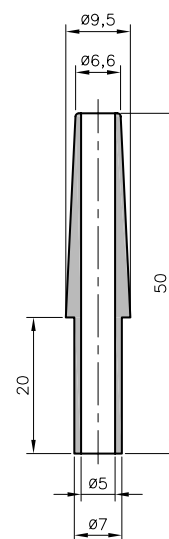


**15-380**  
0253 0062 010

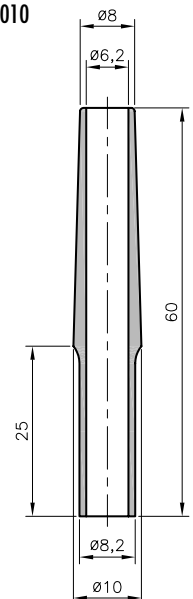


**15-391**  
0253 0063 010

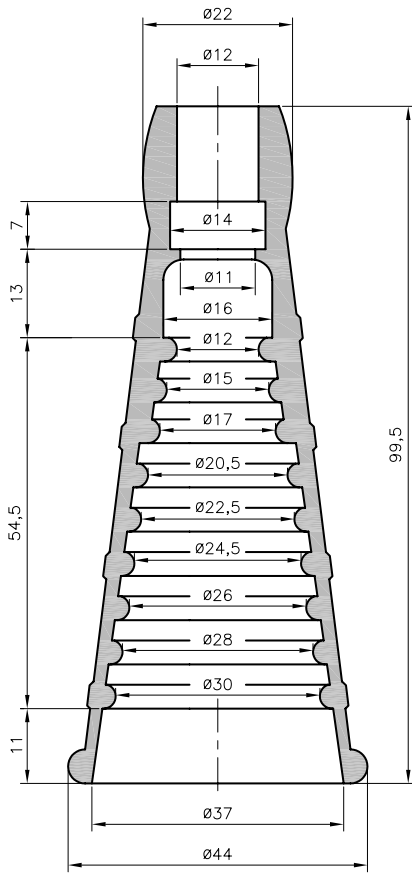


**15-329**  
0253 0060 010

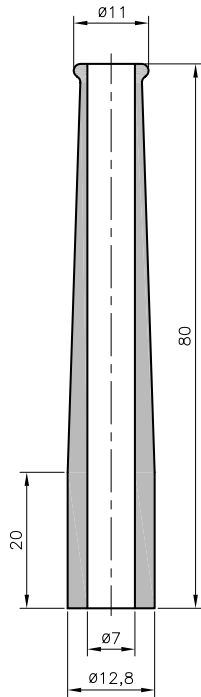


**15-164**  
0253 0018 010

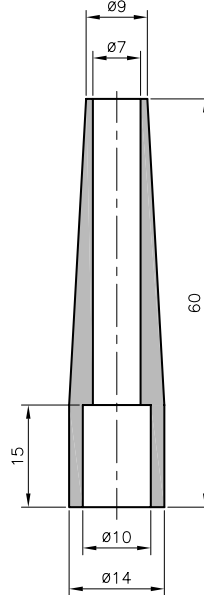


**15-045**  
0253 0005 010

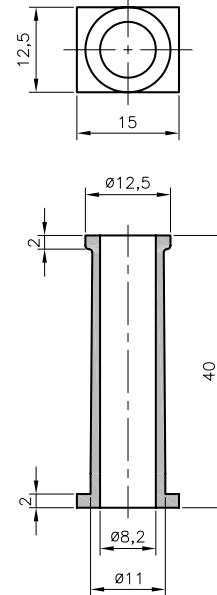


**15-642**  
0253 0078 010

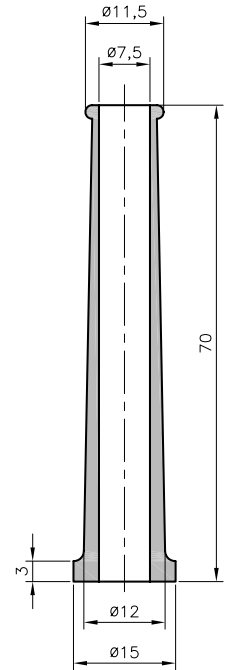


**15-411**  
0253 0052 010

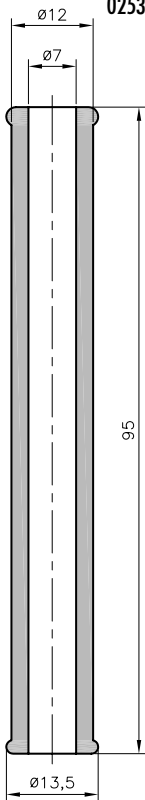


**15-169**  
0253 0019 010

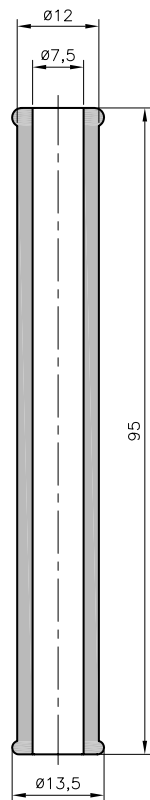


**15-170**  
0253 0020 010

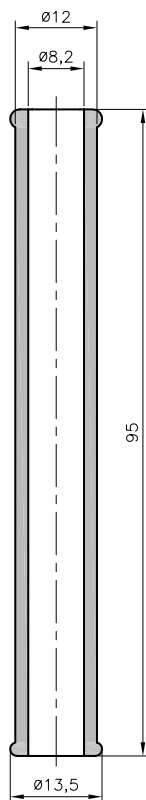


**15-171**  
0253 0021 010

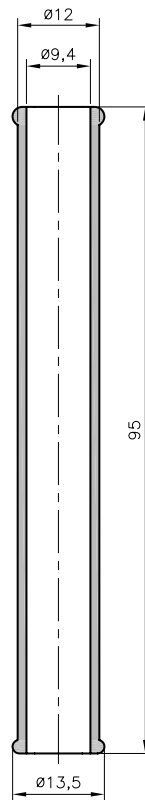



**15-172**  
0253 0022 010

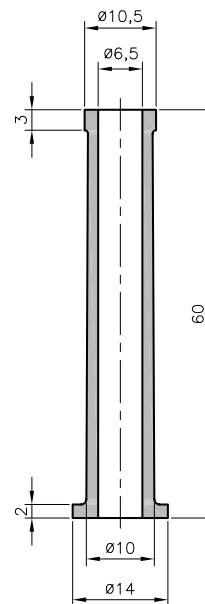


**15-538**  
0253 0064 010

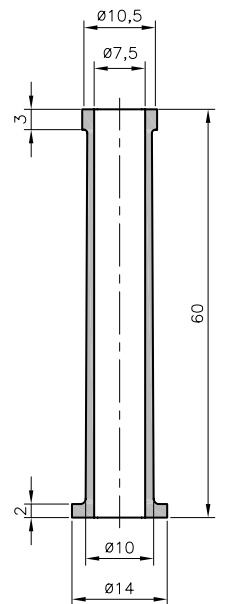


**15-579**  
0253 0066 010

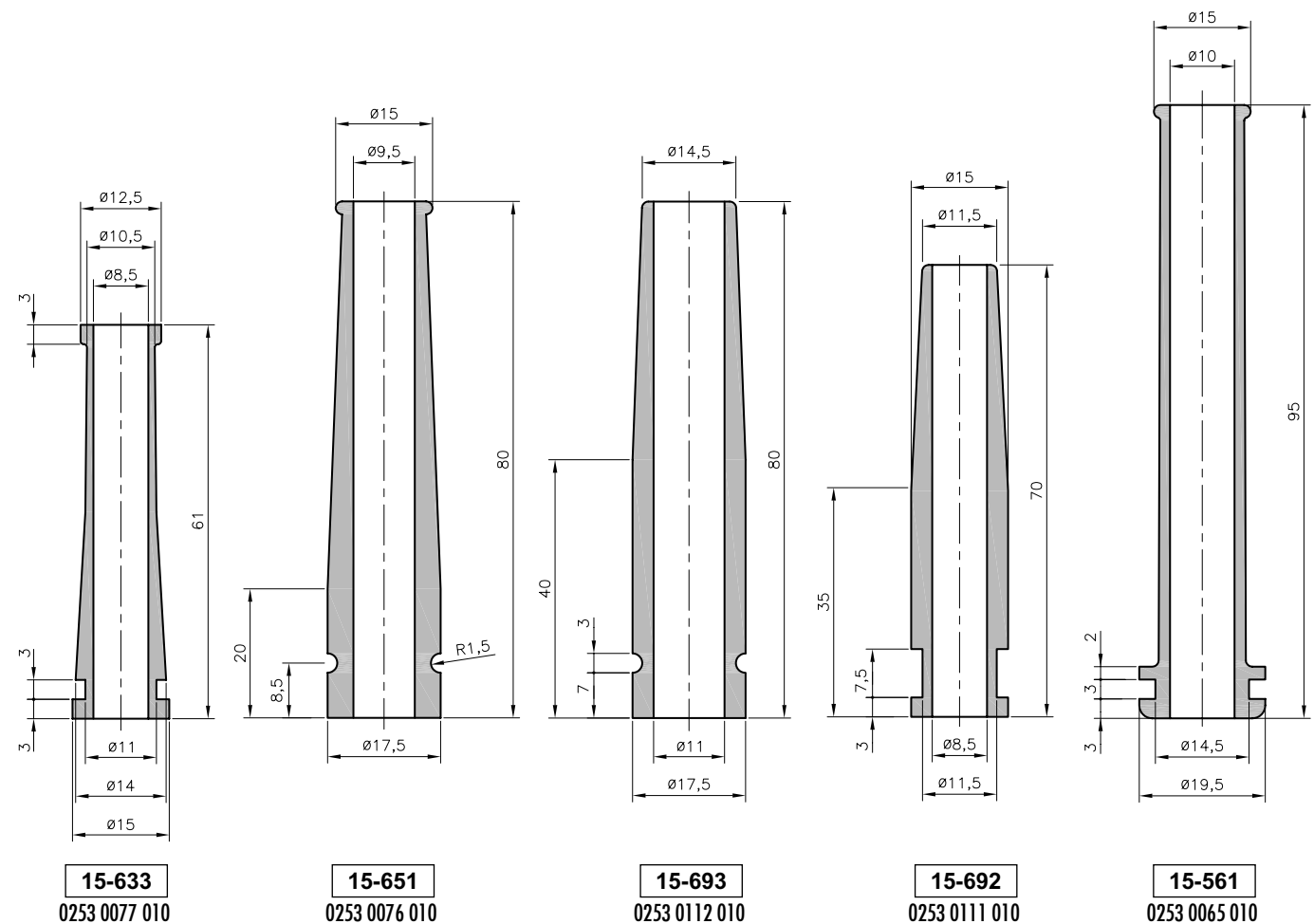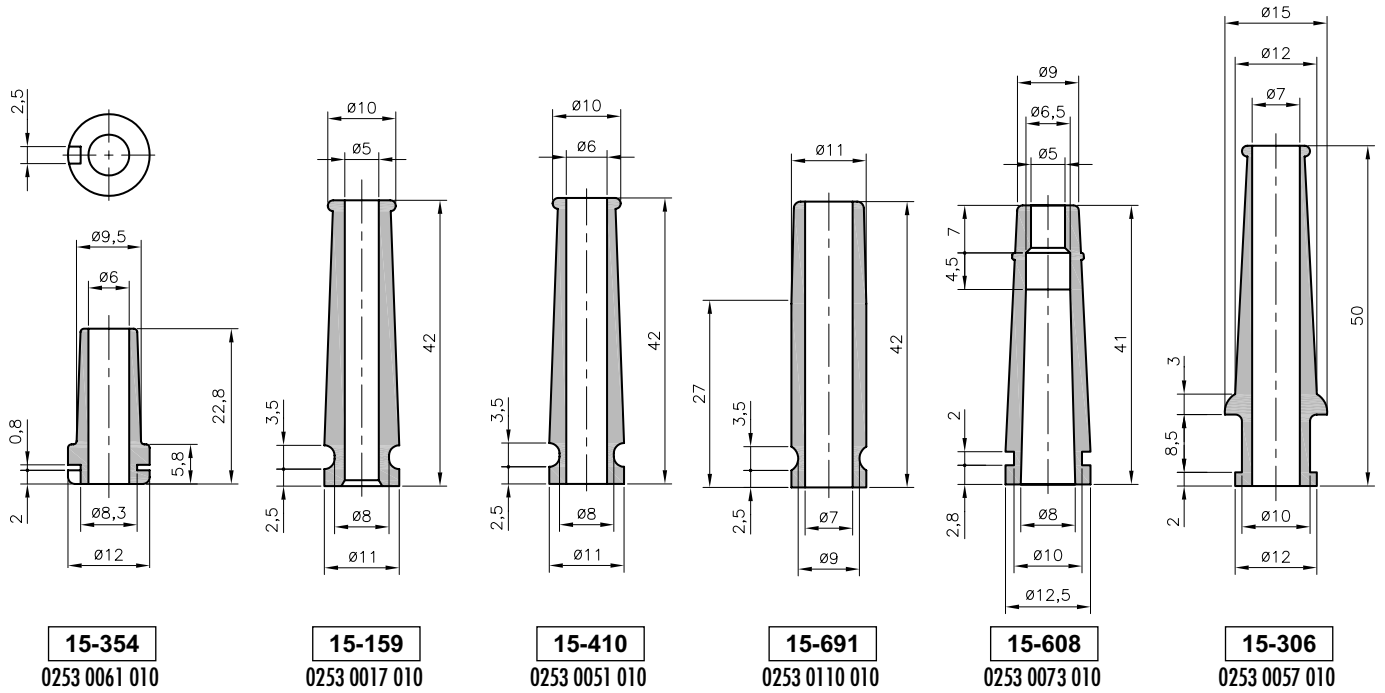


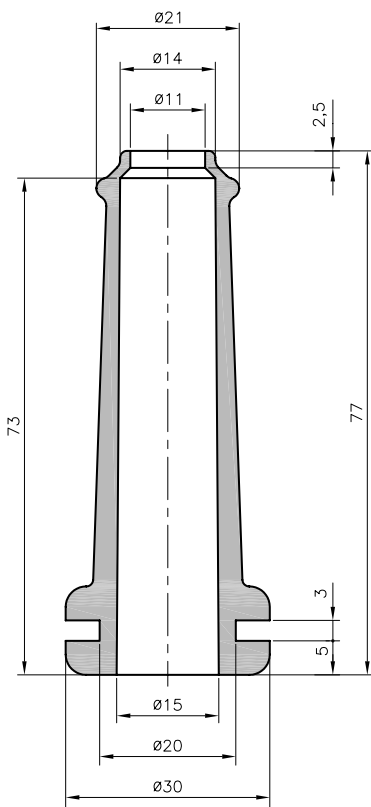


**15-049**  
0253 0008 010

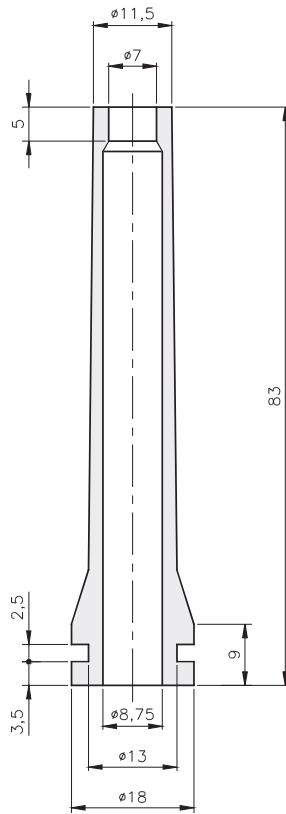


**15-131**  
0253 0015 010

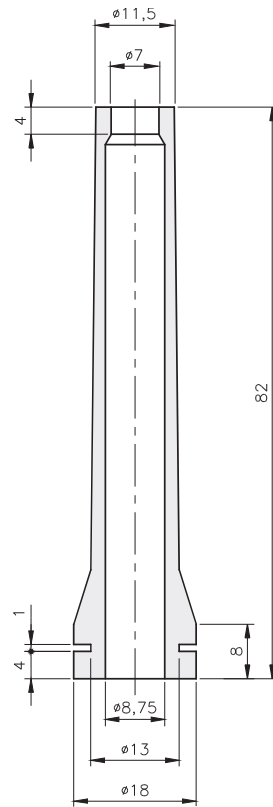


**15-672**  
0253 0092 010

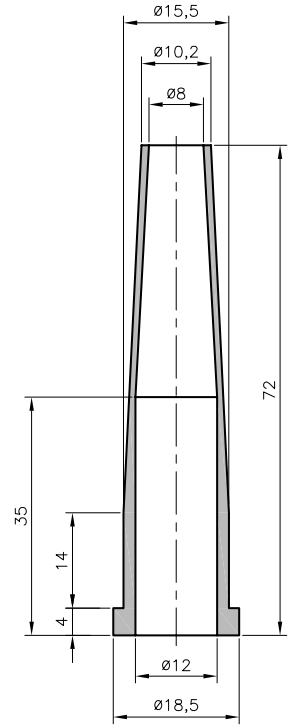


**15-147**  
0253 0016 010

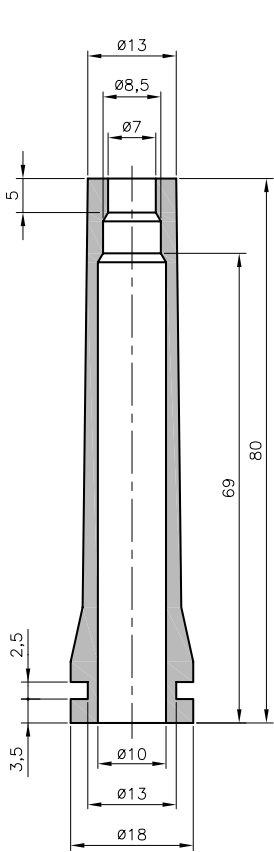


**15-643**  
0253 0079 010

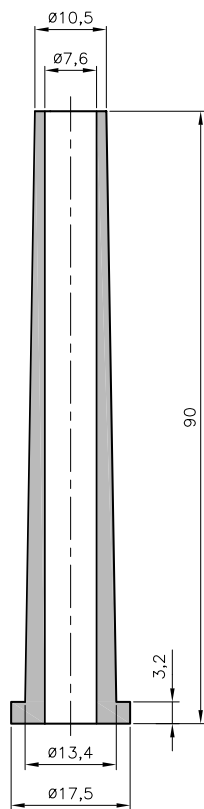


**15-602**  
0253 0072 010

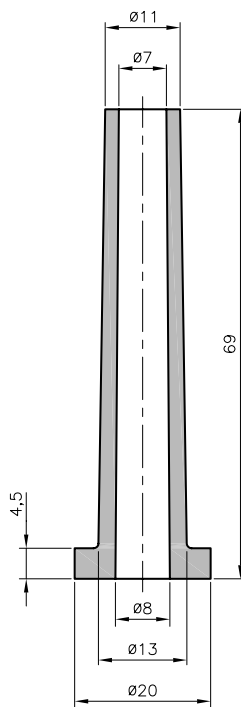


**15-592**  
0253 0070 010

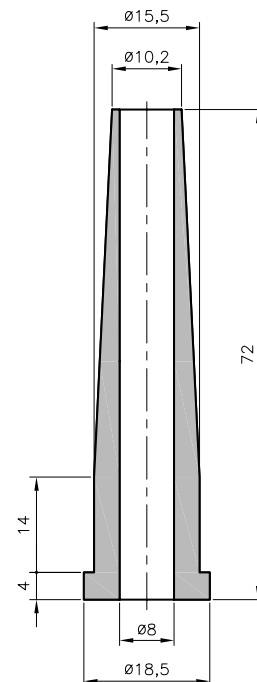


**15-130**  
0253 0014 010

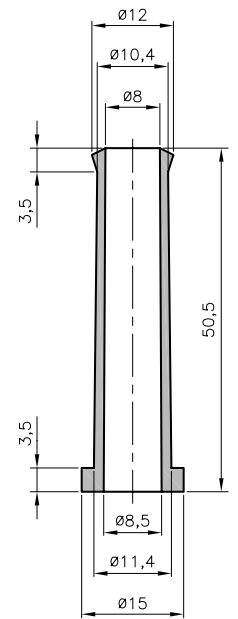


**15-383**  
0253 0056 010

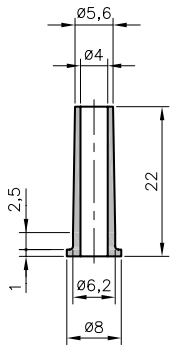


**15-649**  
0253 0075 010

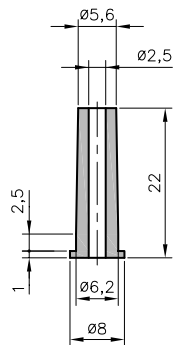


**15-760**  
0253 0113 010

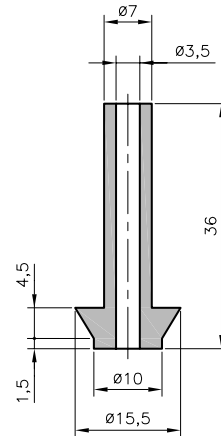


**15-596**  
0253 0071 010

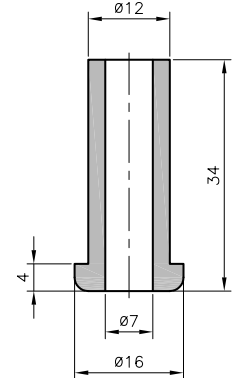


**15-625**  
0252 0319 010

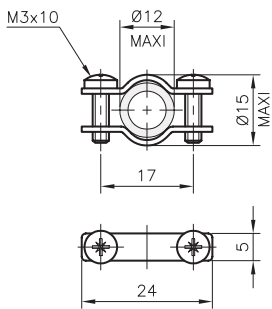


**16-900**  
0684 0054 000

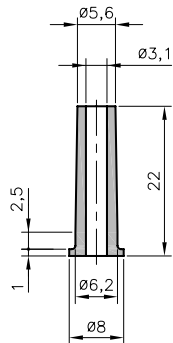


**15-721**  
0253 0003 010

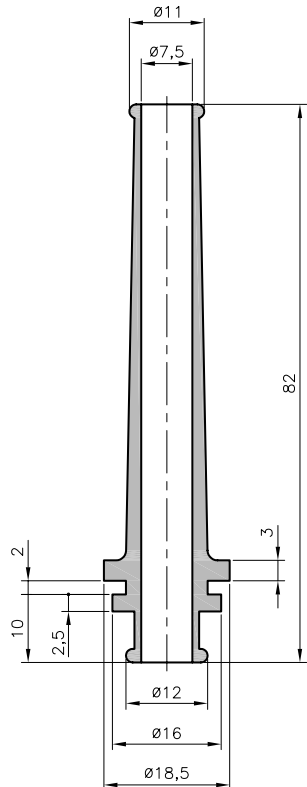


**15-412**  
0253 0053 010

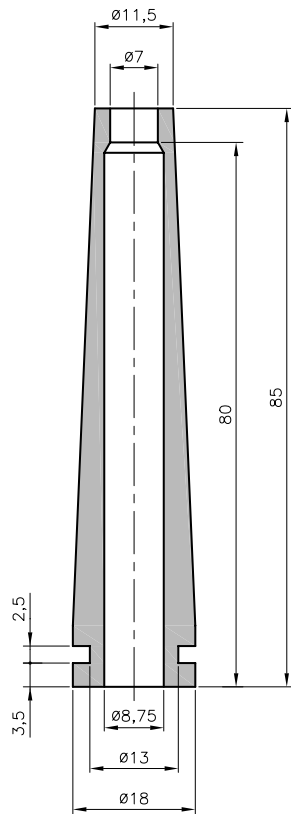

**15-751**  
0253 0091 010

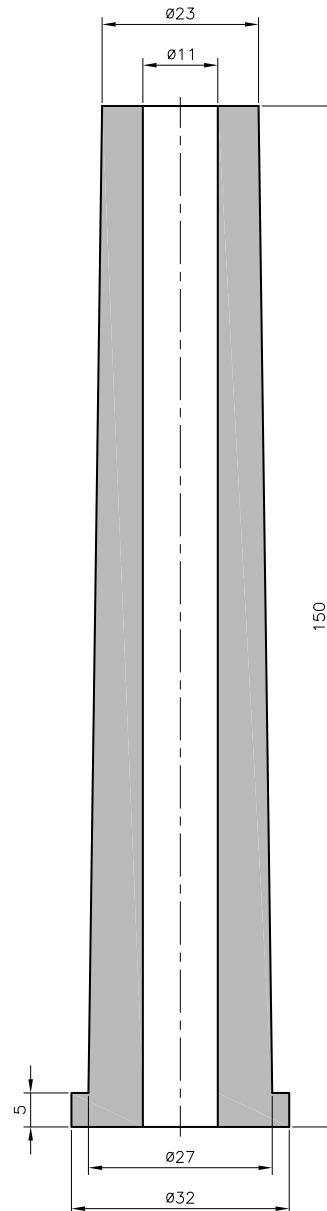


**15-320**  
0253 0059 010

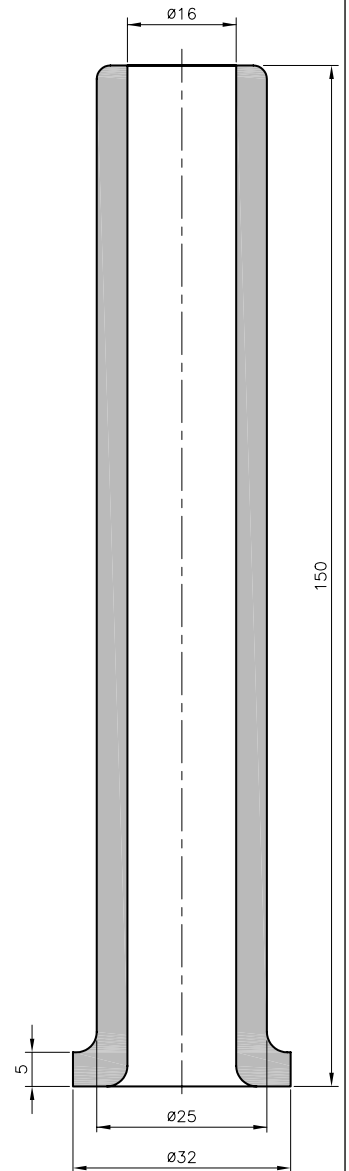


**15-083**  
0253 0013 010


*Nouveau*

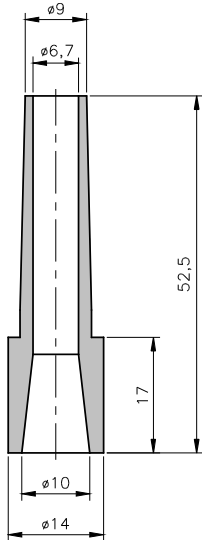


**15-822**  
0253 0117 010

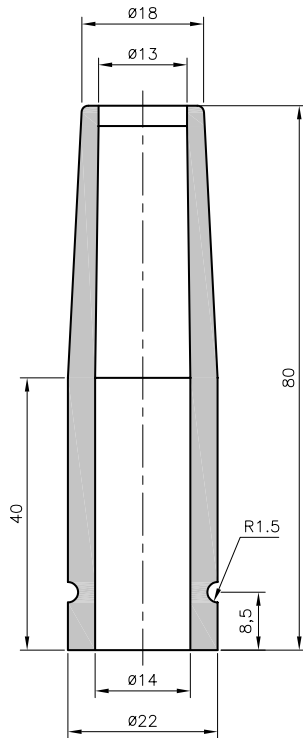


**15-747**  
0253 0083 010

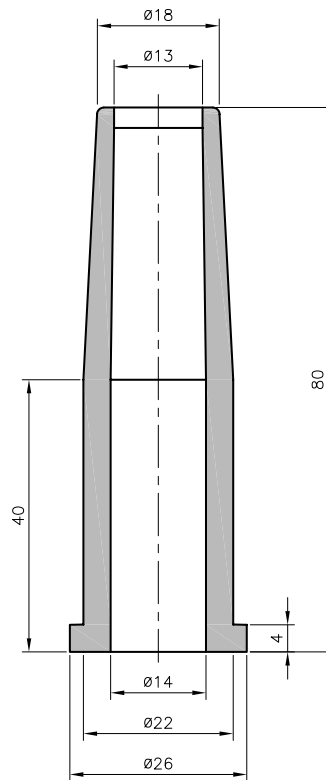


**15-748**  
0253 0084 010

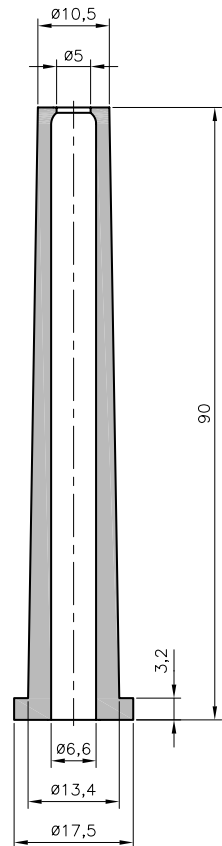


**15-756**  
0253 0085 010

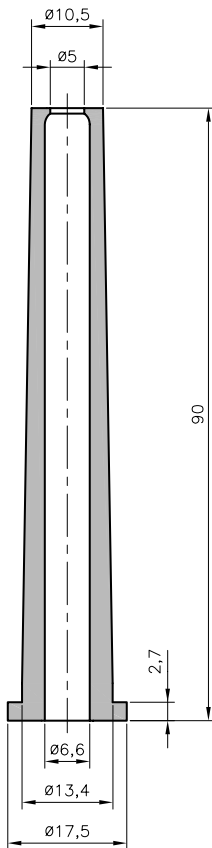


**15-781**  
0253 0087 010

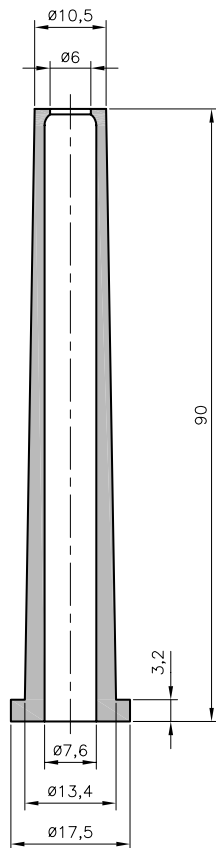

**15-737**  
0253 0080 010

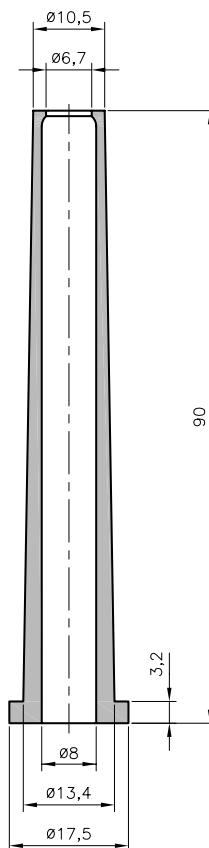

**15-806**  
0253 0114 010

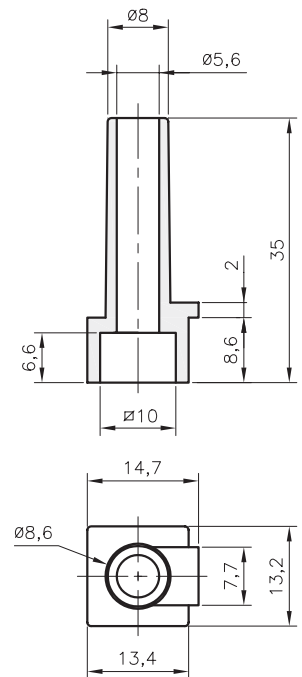

**15-821**  
0253 0115 010