


## Features

- Current rating of 32A for use in demanding applications
- Rotatable operating handle, easy to operate
- Two connections to let you link multiple wires

## RS PRO Lever Connectors, 2-Way, 32A, 24 → 12 AWG Wire, Cage Clamp Termination

RS Stock No. : 0766860, 0766861

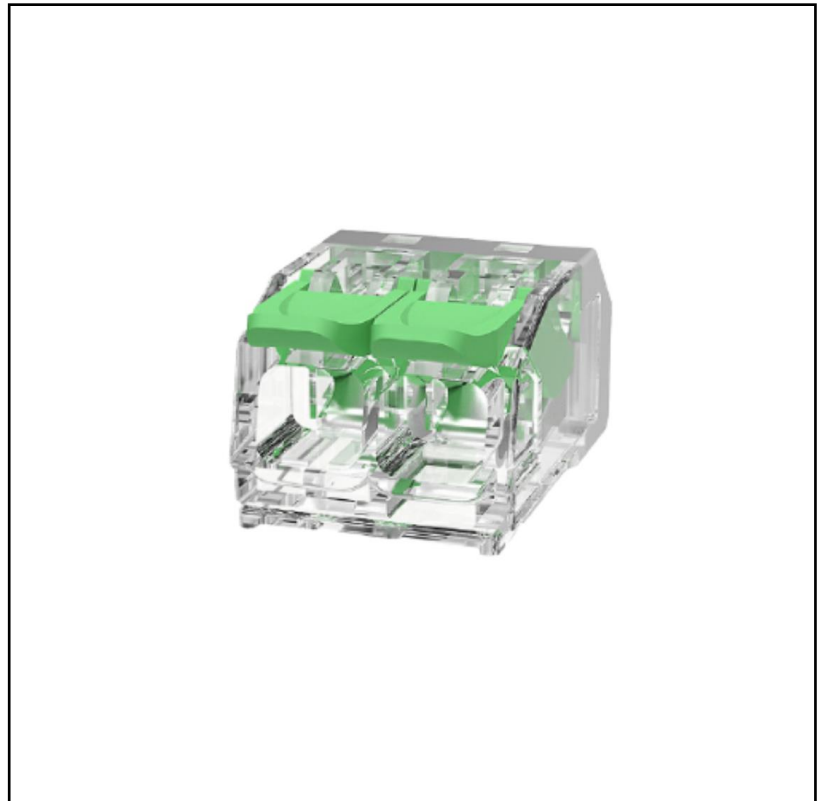

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

### RS PRO Terminal Blocks, 2-Way

For terminate wires in a trice, you can pick this terminal block from RS PRO to secure conductors and make lasting connections. For versatility, the component teams up with solid and stranded leads ranging in size between 24 and 12AWG. Wiring is a piece of cake. Simply pull up the lever, insert the conductor, then push the lever down. Thanks to the transparent casing, you can easily spot connection problems inside the unit.

#### Features & Benefits

- Current rating of 32A for use in demanding applications
- Rotatable operating handle, easy to operate
- Two connections to let you link multiple wires

#### Applications

- Lighting installations
- Electrical networks
- PA systems
- Automotive manufacturing
- Railway applications

## General Specifications

Number of Ways	2
Current Rating	32A
Wire Size	24 → 12 AWG
Termination Method	Cage Clamp
Mounting Type	Cable Mount
Fused	No
Material	Polycarbonate
Voltage Rating	450 V
Cable CSA	4mm <sup>2</sup>
Colour	Clear
Maximum Operating Temperature	85°C
Gender	Female
Enclosed	Yes

## Approvals

<b>Declarations</b>	REACH DoC
<b>Standards Met/Certification</b>	CE/RoHS DoC

## Similar Products

Stock No.	Brand	Product Name	Number of Way	Wire Size	Current Rating
XXX-XXXX FASTCONN2	RS PRO	Terminal Block	2	24 → 12 AWG	32A
XXX-XXXX FASTCONN3	RS PRO	Terminal Block	3	24 → 12 AWG	32A
XXX-XXXX FASTCONN5	RS PRO	Terminal Block	5	24 → 12 AWG	32A