



by Honeywell

## Technical Specifications

### **PSS WK POSITION. LANYARD 2M, D12mm+2CS20**

12mm rope adjustable lanyard 2m equipped with 2 alloy karabiner 20 mm opening.

**Reference: 1031451**

Features :

Rope:

Raw material: 100% Polyamide

Diameters: 12mm

Breaking strength: >2200 daN



Twist lock karabiners :

Raw material: Alloy


Opening: 20mm

Dimensions : 123 x 70 mm

Breaking strength: > 2200 daN

Weight : 0.45kg

**EN 358**

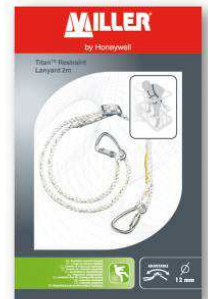

**LAW of 19 MARCH 93**

PPE are products classified in category III, mortal risks, and as such they have to be the object of a periodic inspection for less than twelve months at the time of its use by the qualified person.

For more information, please contact our technical team at 02 48 52 40 42 or by e-mail [techniserv.hsp@honeywell.com](mailto:techniserv.hsp@honeywell.com)

HONEYWELL FALL PROTECTION FRANCE SAS

35-37 rue de la Bidauderie

F - 18100 Vierzon - France

Tel : +33 2 48 52 40 40

Fax : +33 2 48 71 04 97

Web site : [www.honeywellsafety.com](http://www.honeywellsafety.com)