


HDS-Series – Solder Cup

Material Specification:


Insulator:	Glass filled Polyester, Black UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contacts:	Copper Alloy Class 3: 100 inserts min.
Contact Plating:	Selective Gold over Nickel



Plug connector

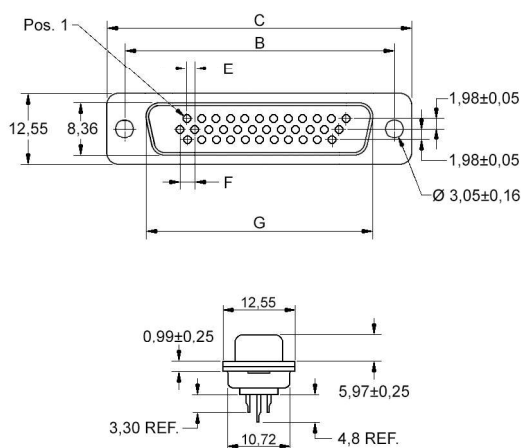

Socket connector

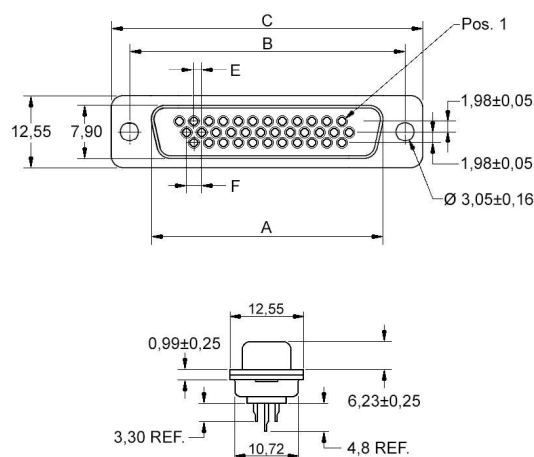


Size	A	B	C	E	F	G
HD15	16,33	24,99	30,81	1,145	2,99	16,62
HD26	24,66	33,32	39,14	1,145	2,99	25,25
HD44	38,38	47,04	53,04	1,145	2,99	38,96
HD62	54,84	63,50	69,32	1,205	2,41	55,25

Size 78 available on request.

Order Codes - Standard Type - with Ø 3.05mm Through Hole

Option X (Standard)

Ø 3.05mm Holes

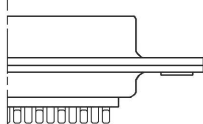

Plug Connector

15	2101-0300-01	HDS-15-MTBS
26	2101-0300-02	HDS-26-MTBS
44	2101-0300-03	HDS-44-MTBS
62	2101-0300-04	HDS-62-MTBS
78	On request	

Socket Connector

09	2101-0300-11	HDS-15-FTBS
15	2101-0300-12	HDS-26-FTBS
25	2101-0300-13	HDS-44-FTBS
37	2101-0300-14	HDS-62-FTBS
78	On request	



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com