


1748-BV0

Self-extinguishing nylon cable ties, white

CE

Material: polyamide PA 6.6
 Self extinguishing class: UL 94-V0
 Working temperature: -40 °C ÷ +85 °C
 Minimum installation temperature: -10 °C
 Resistance to chemicals: Good
 resistance to bases, oils, greases, chloride solvents. Limited resistance to acids.
 Not resistant to phenols
 Reference standards: EN 62275:2015-02
 Classification: type 1 (EN)

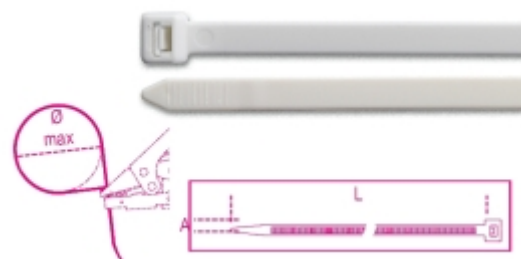

Please indicate number of cable ties, and not of packages, in your order

	art.	A mm	L mm	Ø MAX mm	F MAX N
BMB1025V0	BMB1025V0	2.5	100	20.5	80
BMB1536V0	BMB1536V0	3.6	150	36.0	180
BMB2036V0	BMB2036V0	3.6	200	52.5	180
BMB2048V0	BMB2048V0	4.8	200	49.5	230
BMB3048V0	BMB3048V0	4.8	300	81.0	230
BMB3848V0	BMB3848V0	4.8	370	106.7	230
BMB3876V0	BMB3876V0	7.6	370	106.7	540