




97-1/4

1/4" Open End Insert for 9 mm x 12 mm Rectangular Connector Wrench



PRODUCT DETAILS

- Insert is fixed to the torque wrench by a spring-loaded retractable pin
- Range covers 9x12 and 14x18 receivers, from 1/4 to 1.1/4 inch openings, from 6 to 360 N·m
- Sizes with * in torque length require a target torque setting calculation
- Suitable for 7465, 74W9, 74W14, 74P9, 74P14, IZO-D, TAW9, TAW14, TAWM9, TAWM14 wrenches

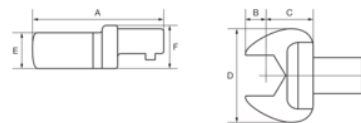

Follow the Fish!



PRODUCT ATTRIBUTES

Product				A	B	C	D	E	F	
97-1/4	1/4 in	9x12 mm	6 N·m	40 mm	7,5 mm	17,5 mm	22 mm	5 mm	17 mm	0.03 kg

