



Includes a high quality mechanical backdraft shutter that prevents outside air coming into building when fan is switched off.

EDM

WALL MOUNTED FAN



Whether wall or ceiling mounted, the EDM exhausts stale and moist air from homes and commercial buildings. The robust mechanically driven backdraft shutter prevents dust from infiltrating it even when switched off, making it perfect for homes and on-site offices in harsh conditions.

- Made from tough injection moulded plastic.
- Internal thermal motor cut out protection.
- 220-240V, single-phase, 50Hz.
- Certificate of Approval number: ESV140558.

BULK OPTION

- Available in plain carton only.
- Minimum order quantity of 10
- Product code: EDM-300C-BULK.


ACCESSORIES

- External Grilles.
- Flexible Duct - Fire Rated AS/NZS 4254.
- Wall Tubes.

MODEL NO.	M ³ /HR [†]	L/SEC [†]	FAN SPEED RPM	AVG. dB(A) @ 3M	WATTS	VOLTS	IP RATING
EDM-300C	280	78	2200	41	35	240	IPX4

[†] Air flow without duct and fittings

See page 109 for performance curves.

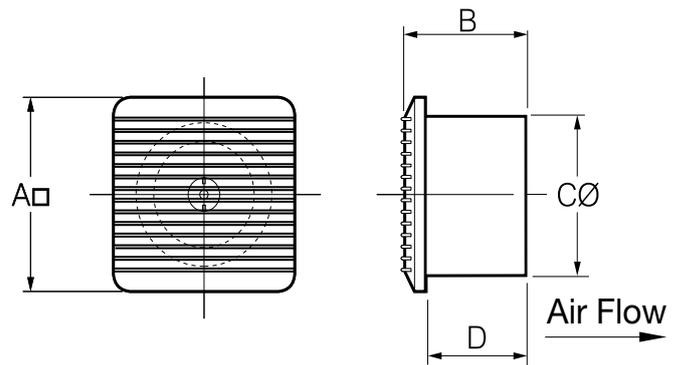

MODEL NO.	DUCT SIZE	A	B	C	D
EDM-300C	150	200	129	148	104



The EDM's electric shutters operate using wax motor technology. The wax pot is a paraffin-filled cylinder designed to open and close the shutter with a smooth and gentle stroke. This reduces noise and ensures faultless operation every time.