

Features

- Pneumatic flush cutting tools.
- The TPP-TR-6000-R is a handy pneumatic cutter suitable for cutting conventional components.
- Maximum cutting capacity Ø 1.60 mm copper wire.
- Blades are made in Italy from a special steel.
- Blade steel thickness 6 mm.
- Lever activation.
- Made in Italy.
- CE mark.

RS PRO Pneumatic Side Cutter for flush cut.

RS Stock No.: (0429709)



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


- 0429709 is a handy pneumatic cutter suitable for cutting conventional components.
- Handy, light and precise.
- Easily exchangeable replacement blade
- Suitable for cutting conventional components.
- Maximum cutting capacity Ø 1.60 mm copper wire.
- Blades are made in Italy from a special steel.
- Blade steel thickness 6 mm.
- Lever activation.
- Made in Italy.
- CE mark.

General Specifications


Cutter Type	flush cutter
Tip Style	20° angled flush cutter
Blade Material	Tempered high carbon steel
Body Material	Different materials (Aluminium, Stainless & Iron Steel, Plastic (lever))

Mechanical Specifications

Cutting capacities	Ø 1.60mm (14 awg) copper wire
Cutting force	90 kg
Blade Steel thickness	6mm
Blade angle	20°
Dimensions	165 x 35mm
Weight	300 g
Compressed air pressure	6 – 7 bars (tube Ø 6)
Consumption	3.5 NL/min
CE mark	Yes

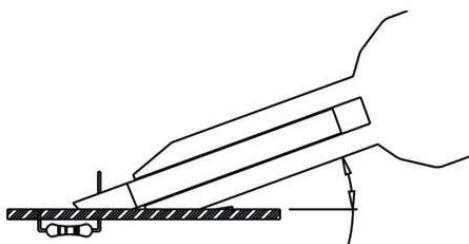

Replacement blade:

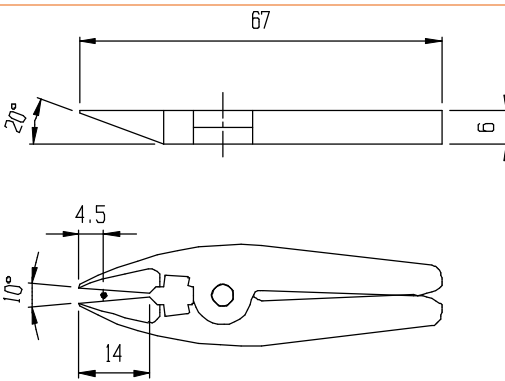	Spare cutting blade (flush cut) Order code: 0429711	
---	---	---