


# Grey Thermoplastic Rubber Trolley Wheel 125mm, 150kg

Thermoplastic rubber-tyred wheel

PRODUCT

Article number

381 502

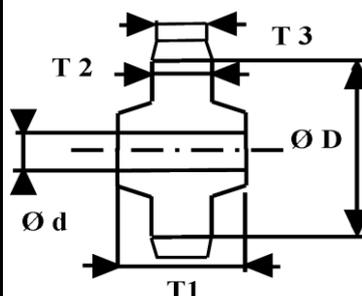

## Product Details

Wheel Rim : made of grey impact-resistant polyamide.  
Tread : grey thermoplastic rubber, integrated type. Non-marking.  
Hub : symmetrical with roller bearing and nylon threadguards  
Delivered with M8x60 bolt.

## Specifications

Wheel Diameter - $\varnothing D \pm 1\%$	<b>125 mm</b>
Hub Type	<b>Roller Bearing</b>
Hub Length T1	<b>34 mm <math>\pm 1</math></b>
Width of Tread T2	<b>45 mm <math>\pm 1</math></b>
Width of Tread-on floor T3	<b>34 mm <math>\pm 1</math></b>
Axle Hole $\varnothing d$	<b><math>\varnothing 12</math> mm</b>
Hardness of tread A $\pm 3$	<b>A 85° Shore</b>
Load capacity	<b>150 Kg</b>
Temperature	<b>-10 / +50 °C</b>
Bolt	<b>Hexagonal Head M8x55</b>
Weight	<b>0,34 Kg</b>

TECHNICAL DATA

## Applications :

Quiet and non-marking materials handling.  
Large nylon threadguards cover the rim and reduce noise  
Lightweight, low starting effort.  
Suitable for all interiors floors (warehouses, offices, shops, kitchens,...).