

## 特点

- 头高度等于柄直径
- 比钛材质更经济高效
- 提供各种螺纹尺寸
- 高质量螺纹设计

## RS M5 Pro 20mm 内六角半圆头 螺钉、本色 不锈钢

RS 号: 232-8265



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与领先品牌相当的质量、而无需支付高昂的价格。

## 商品描述属性

RS PRO 推出种类多样的半圆头凹头螺钉系列。由高质量不锈钢制成，并利用六角头实现简单有效的安装。这些螺钉适用于多种应用，如机器维修或建筑。优质的凹头螺钉具有耐久、坚固的结构，您可以放心使用。所有型号均高度可靠且质量极佳。

## 一般规格

螺纹尺寸	M5
头部形状	六角套筒按钮
材料	不锈钢
表面	普通
螺纹类型	公制
应用	木材加工、家用应用、紧固件和固定件、机器工具和维修、安全防护、面板制造

## 机械规格

长度	20mm
不锈钢类型	316 A4
螺距	0.8mm
头直径范围	9.14mm 至 9.50mm
头部高度范围	2.50mm 至 2.75mm
钥匙尺寸标称范围	3.02mm 至 3.071mm
关键敬业度	1.56
螺纹公差	6g

## 操作环境规格

最高温度	300°C
------	-------

## 认证


合规性 / 认证	rohs 符合性证书, ISO7380, ansi B18
----------	-------------------------------



Please view our full range listing below for all A4, 316 Stainless Steel Self-Colour Hexagon Socket Button Head Screws.

Head Shape	Material	Stainless Steel Type	Thread Size	Length	RS Part No.
Hex Socket Button	Stainless Steel	A4, 316	M3	8 mm	2328142
Hex Socket Button	Stainless Steel	A4, 316	M3	10 mm	2328158
Hex Socket Button	Stainless Steel	A4, 316	M3	12 mm	2328164
Hex Socket Button	Stainless Steel	A4, 316	M4	8 mm	2328170
Hex Socket Button	Stainless Steel	A4, 316	M4	10 mm	2328186
Hex Socket Button	Stainless Steel	A4, 316	M4	12 mm	2328209
Hex Socket Button	Stainless Steel	A4, 316	M4	16 mm	2328215
Hex Socket Button	Stainless Steel	A4, 316	M5	10 mm	2328221
Hex Socket Button	Stainless Steel	A4, 316	M5	12 mm	2328237
Hex Socket Button	Stainless Steel	A4, 316	M5	16 mm	2328243
Hex Socket Button	Stainless Steel	A4, 316	M5	20 mm	2328265
Hex Socket Button	Stainless Steel	A4, 316	M5	25 mm	3044643
Hex Socket Button	Stainless Steel	A4, 316	M5	30 mm	3044659
Hex Socket Button	Stainless Steel	A4, 316	M5	40 mm	3044766
Hex Socket Button	Stainless Steel	A4, 316	M5	50 mm	3044744

Hex Socket Button	Stainless Steel	A4, 316	M6	12 mm	2328271
Hex Socket Button	Stainless Steel	A4, 316	M6	16 mm	2328287
Hex Socket Button	Stainless Steel	A4, 316	M6	20 mm	2328293
Hex Socket Button	Stainless Steel	A4, 316	M6	25 mm	2328300
Hex Socket Button	Stainless Steel	A4, 316	M6	30 mm	3044738
Hex Socket Button	Stainless Steel	A4, 316	M6	40 mm	3044722
Hex Socket Button	Stainless Steel	A4, 316	M6	50 mm	3044716
Hex Socket Button	Stainless Steel	A4, 316	M6	60 mm	3044700
Hex Socket Button	Stainless Steel	A4, 316	M8	12 mm	2328322
Hex Socket Button	Stainless Steel	A4, 316	M8	16 mm	2328338
Hex Socket Button	Stainless Steel	A4, 316	M8	20 mm	2328344
Hex Socket Button	Stainless Steel	A4, 316	M8	25 mm	2328350
Hex Socket Button	Stainless Steel	A4, 316	M8	30 mm	3044687
Hex Socket Button	Stainless Steel	A4, 316	M8	40 mm	3044671
Hex Socket Button	Stainless Steel	A4, 316	M8	50 mm	3044665
Hex Socket Button	Stainless Steel	A4, 316	M8	60 mm	3044772

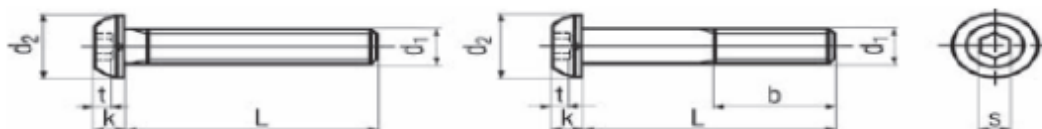

Thread Size d1		M3	M4	M5	M6	M8	M10	M12	M16
Thread Pitch		0.5	0.7	0.8	1	1.25	1.5	1.75	2
~ISO 7380 Head Dia. d2	min.	5.4	7.24	9.14	10.07	13.57	17.07	20.48	27.48
	max.	5.7	7.60	9.50	10.50	14.00	17.50	21.00	28.00
ANSI B 18.3.4M Head Dia. d2	min.	5.4	7.24	9.14	10.07	13.57	17.07	20.48	27.48
	max.	5.7	7.60	9.50	10.50	14.00	17.50	21.00	28.00
~ISO 7380 Head Height k	min.	1.40	1.95	2.50	3.00	4.10	5.20	6.24	8.44
	max.	1.65	2.20	2.75	3.30	4.40	5.50	6.60	8.80
ANSI B 18.3.4M Head Height k	min.	1.43	1.95	2.50	3.00	4.05	5.20	6.24	8.44
	max.	1.65	2.20	2.75	3.30	4.40	5.50	6.60	8.80
~ISO 7380 Key Size s	Nominal Size	2	2.5	3	4	5	6	8	10
	min.	2.020	2.52	3.020	4.020	5.020	6.020	8.025	10.025
	max.	2.045	2.56	3.071	4.084	5.084	6.095	8.115	10.115
ANSI B 18.3.4M Key Size s	Nominal Size	2	2.5	3	4	5	6	8	10
	min.	2.020	2.52	3.020	4.020	5.020	6.020	8.025	10.025
	max.	2.045	2.56	3.071	4.084	5.084	6.095	8.115	10.115
~ISO 7380 Key Engagement t	min.	1.04	1.3	1.56	2.08	2.60	3.12	4.16	5.20
ANSI B 18.3.4M Key Engagement t	min.	1.04	1.3	1.56	2.08	2.60	3.12	4.16	5.20

