


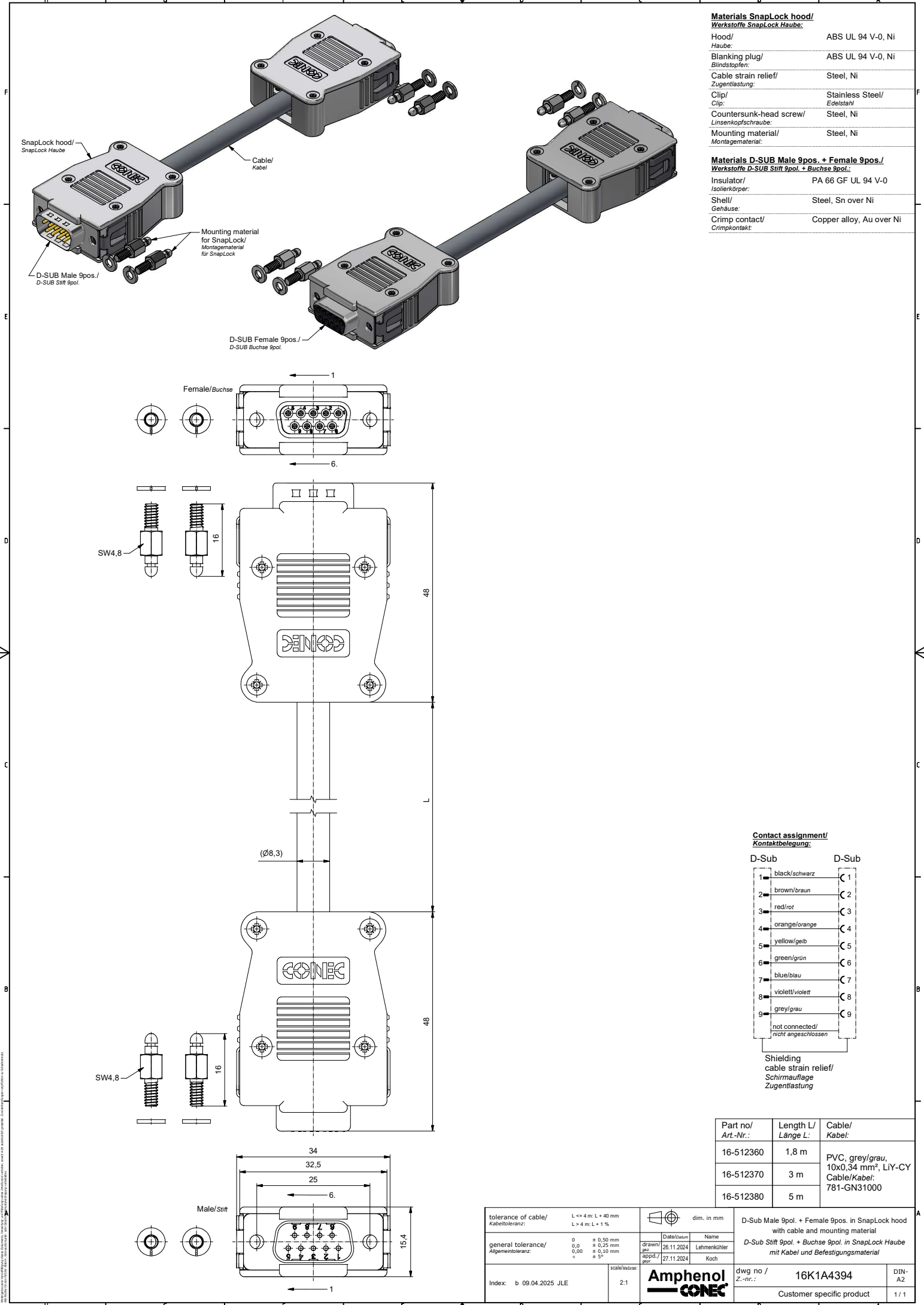

Materials SnapLock hood/ Werkstoffe SnapLock Haube:		
Hood/ Haube:	ABS UL 94 V-0, Ni	
Blanking plug/ Blindstopfen:	ABS UL 94 V-0, Ni	
Cable strain relief/ Zugentlastung:	Steel, Ni	
Clip/ Clip:	Stainless Steel/ Edelstahl	
Countersunk-head screw/ Linsenkopfschraube:	Steel, Ni	
Mounting material/ Montagematerial:	Steel, Ni	

Materials D-SUB Male 9pos. + Female 9pos./ Werkstoffe D-SUB Stift 9pol. + Buchse 9pol.:		
Insulator/ Isolierkörper:	PA 66 GF UL 94 V-0	
Shell/ Gehäuse:	Steel, Sn over Ni	
Crimp contact/ Crimpkontakt:	Copper alloy, Au over Ni	

Contact assignment/ Kontaktbelegung:	
D-Sub	D-Sub
1 black/schwarz	1
2 brown/braun	2
3 red/rot	3
4 orange/orange	4
5 yellow/gelb	5
6 green/grün	6
7 blue/blau	7
8 violett/violett	8
9 grey/grau	9
not connected/ nicht angeschlossen	
Shielding cable strain relief/ Schirmauflage Zugentlastung	

Part no/ Art.-Nr.:	Length L/ Länge L:	Cable/ Kabel:
16-512360	1,8 m	PVC, grey/grau, 10x0,34 mm², LiY-CY Cable/Kabel: 781-GN31000
16-512370	3 m	
16-512380	5 m	

tolerance of cable/ Kabeltoleranz:		dim. in mm	
L <= 4 m: L + 40 mm		Date/ Datum	
L > 4 m: L + 1 %		Name	
general tolerance/ Allgemeintoleranz:		drawn/ gezt.	
0 ± 0,50 mm		26.11.2024	
0,0 ± 0,25 mm		Lehmenkühler	
0,00 ± 0,10 mm		27.11.2024	
± 5°		Koch	
Index: b 09.04.2025 JLE		scale/ Maßstab:	
		2:1	
		Amphenol CONEC	
		D-Sub Male 9pol. + Female 9pos. in SnapLock hood with cable and mounting material	
		D-Sub Stift 9pol. + Buchse 9pol. in SnapLock Haube mit Kabel und Befestigungsmaterial	
		dwg no / Z.-nr.:	
		16K1A4394	
		DIN-A2	
		Customer specific product	
		1 / 1	