
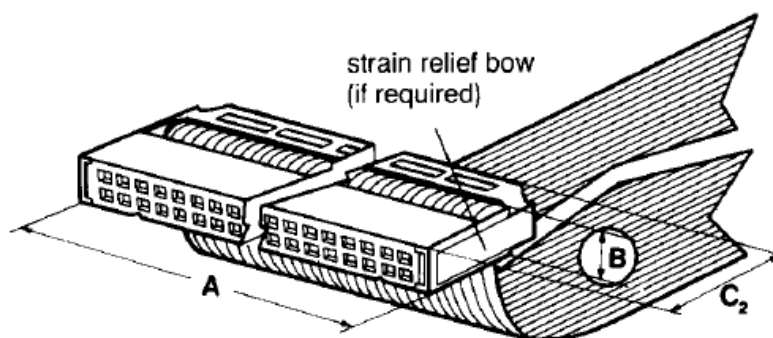


Datasheet

Socket Connectors

RS Stock number 458-544

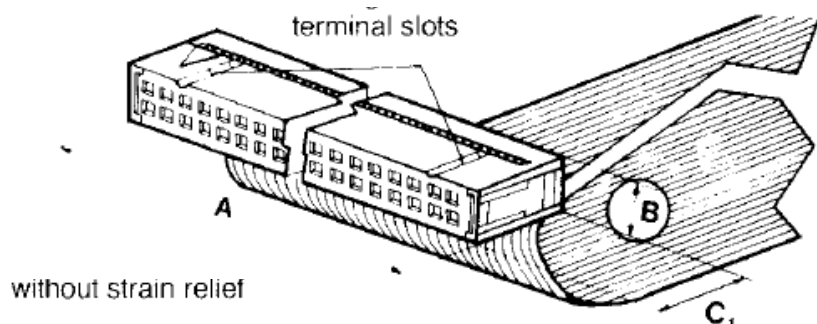

| Stock no. | No. of Ways | A | B | C ₁ | C ₂ |
|-----------|-------------|-------|-----|----------------|----------------|
| 458-471 | 10 | 17.3 | 6.1 | 10.7 | 16.5 |
| 458-487 | 14 | 22.4 | 6.1 | 10.7 | 16.5 |
| 458-500 | 20 | 30.0 | 6.1 | 10.7 | 16.5 |
| 458-516 | 26 | 37.60 | 6.1 | 10.7 | 16.5 |
| 458-522 | 34 | 47.80 | 6.1 | 10.7 | 16.5 |
| 458-538 | 40 | 55.40 | 6.1 | 10.7 | 16.5 |
| 458-544 | 50 | 68.10 | 6.1 | 10.7 | 16.5 |



ENGLISH

Specifications:

| | |
|------------------------------|--|
| Insulators: | Polyester GV, VO, UL 94, colour grey, RAL 7035 |
| Operating Temperature Range: | -65°C to +150°C |
| Current Carrying Capacity: | 1A |
| Tensile Strength: | 1000Veff |
| Contacts: | Copper alloy |