 



COLOR VARIFOCAL DOME CAMERA

7769371

► CAUTION

- Do not open or strike this equipment. Sensitive electronics inside are vulnerable to excessive shock.
- Do not install the equipment near any naked flames or heat sources. Excessive heat could damage this unit.
- Do not cover cloth or to install this unit in poorly ventilated places. This may lead to overheating.
- Do not continue to operate if there appears to be fault.
- If the unit ceases to function, contact qualified service personnel for help.
- Do not touch the power connection with wet hands. Risk of short circuit or electric shock.
- Do not damage the power cord or leave it under pressure. Risk of fire or shock circuit.

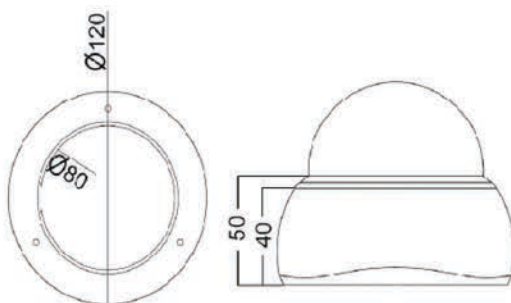

FEATURE

- 1/3" COLOR SONY SUPER HAD II
- HIGH RESOLUTION (80Φ + 120Φ)**
- 700TV Line
- Min. Illumination : 0.005 Lux(F:1.2)
- OSD Control - Digital WDR/BLC/HSBLC/LSC
- 2.8~12mm DC IRIS LENS
- Power Source : DC 12V(6.5~28V)
- Vari-Focal Lens Type
- Internal Adjustment OSD button

SPECIFICATION

| | | | |
|-----------------------|------------------------|--|----------------------------------|
| Image Device | | 1/3" Color SONY Super HAD II CCD | |
| Picture Elements | | 1020(H)×508(V) | 1020(H)×582(V) |
| Scanning System | | 525 Lines, 2:1 Interlace | 625 Lines, 2:1 Interlace |
| Sync System | | Internal Synchronization | |
| Horizontal Resolution | | 700 TV Line | |
| Video Output | | 1Vp-p 75Ω | |
| S/N Ratio | | More Than 50dB (AGC Off) | |
| Gamma Characteristic | | 0.45 | |
| Electronic Shutter | | 1/60~1/100,000sec (Auto) | 1/50~1/100,000sec (Auto) |
| LENS | | DC Iris 2.8mm ~ 12mm Varifocal lens | |
| Smear Effect | | 0.005% | |
| Minimum Illumination | | 0.005 Lux (F:1.2) | |
| Power Consumption | | DC 12V(6.5~28V), 100mA | |
| Operation Temperature | | -10℃ ~ +50℃, RH95% Max (14°F~122°F) | |
| Storage Temperature | | -20℃ ~ +60℃, RH95% Max | |
| OSD Control | White Balance | ATW(1800°K ~ 10,500°K) / Push / User1 / User2 / Anti CR / Manual / Push-Lock | |
| | Exposure | ELC | |
| | High Speed Shutter | Auto / Manual (1/60~1/10,000sec) | Auto / Manual (1/50~1/10,000sec) |
| | Backlight Compensation | ATR / BLC / HLC | |
| | Privacy Masking | 8 Zone | |
| | Day & Night | Auto / Color / BW / EXT1 / EXT2 | |
| | Motion Detection | Off / On | |
| | 2D-DNR | Off / On (Adjustable) | |
| | Digital Effect | Off / Mirror | |
| | Sharpness | Adjustable | |
| Housing | | P.C / ABS Resin(body) | |
| Dimension(mm) | | (80Φ+120Φ) × 95 | |
| Weight | | approx. 300g | |
| Cable(option) | | Standard 500mm BNC/DC Jack | |