

SHOWA

546W

CUT PROTECTION

Polyurethane coated safety glove with an HPPE/duracoil polyester liner


Ultra-comfortable multi-purpose glove with durable cut resistant properties for precision handling. Engineered DURACoil liner reinforced with HPPE providing level C cut resistance.

Features

- ▲ Multifilament polyester wrapping DURACoil liner reinforced with HPPE provides effective protection against cuts
- ▲ Lightweight and flexible with a Polyurethane coated palm for good grip & aeration
- ▲ PU foamed coating protects the hand from light oils, grease and abrasions while remaining breathable
- ▲ Provides maximum comfort when performing delicate tasks
- ▲ Unique SHOWA ergonomic shape that replicates the natural curve of the human hand for enhanced dexterity and longer use
- ▲ Seamless knit designed to prevent irritation



Certifications

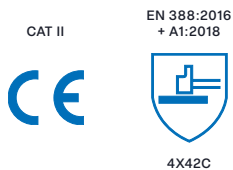

Suitable industries & applications

Industries

- ▲ Aerospace
- ▲ Automotive
- ▲ Manufacturing

- ▲ Waste and Recycling
- ▲ Highways and Infrastructure

Applications

- ▲ Component and Product Assembly
- ▲ Bottling and Canning
- ▲ Cleanroom
- ▲ Infrastructure Engineering
- ▲ Laboratory Analysis
- ▲ Pharmacists

Europe

sales@globus.com
+44 (0)161 877 4747
+44 (0)161 877 4746

Middle East & Africa

sales.gcc@globusgroup.com
+971 4 882 9962
+971 4 882 9963

Americas

salesusa@globusgroup.com
+1 83 337 54747

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment. The manufacturer reserves the right to make any modifications it deems necessary.



SHOWA

546W

CUT PROTECTION

Polyurethane coated safety glove with an HPPE/duracoil polyester liner

Product information

Materials	Liner:	13 Gauge Engineered HPPE, Polyester
	Coating:	Polyurethane
Colour	White	
Cuff Style	Elasticated Knit Wrist	

Ordering information

S	SHO546W1	Items per Pack 10 x Pairs
M	SHO546W2	
L	SHO546W3	Items per Case 120 x Pairs
XL	SHO546W4	
XXL	SHO546W5	

Additional information

Certification legend



or click [here](#)

Declaration of conformity



or click [here](#)

View product online



or click [here](#)

Europe

sales@globus.com
+44 (0)161 877 4747
+44 (0)161 877 4746

Middle East & Africa

sales.gcc@globusgroup.com
+971 4 882 9962
+971 4 882 9963

Americas

salesusa@globusgroup.com
+1 83 337 54747

Globus Group, T2 Trafford Point, Twining Road, Trafford Park, Manchester, M17 1SH, UNITED KINGDOM
Globus EMEA FZE, Jafza One, Tower A, Office 2201, Jebel Ali, PO Box 61195, Dubai, UNITED ARAB EMIRATES
Globus Americas LLC, 45 Rockefeller Plaza, Suite 2000, New York City, New York, 10111, USA

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment.
The manufacturer reserves the right to make any modifications it deems necessary.

 **GLOBUS**