



All Polyester Vertical PCB Header: 2.54mm, Breakaway, MTA 100 (27)

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 240°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought

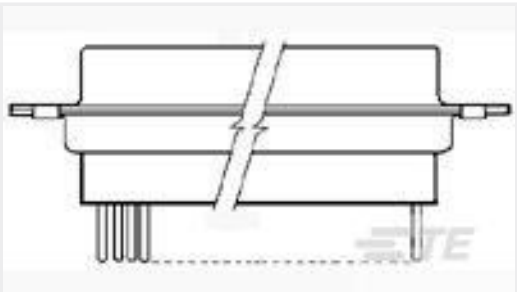

TE Part #208866-1
PLUG ASSY,15 POSN,AMPLIMITE



TE Part #7-456134-9
CRIMPER INSUL F




TE Part #CAT-104MTA-PVBRH
Polyester Vertical PCB Header: 2.54 mm, Breakaway, MTA 100



TE Part #1986775-4
SCREWLESS, SW,4P,5.08 PCB, Low Amp




TE Part #3-2176363-6
RQ 0402 1K0 0.1% 10PPM 5K RL

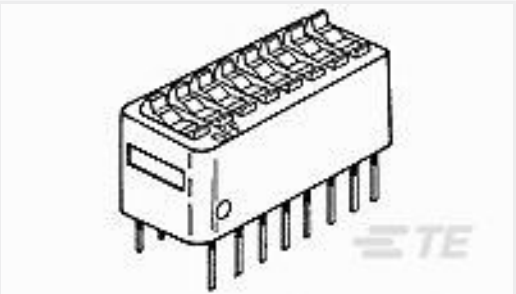

TE Part #435166-5
DIP SW ASSY-BLK SPST-8POS



TE Part #350643-1
12P CMNL HDR ASSY NATL

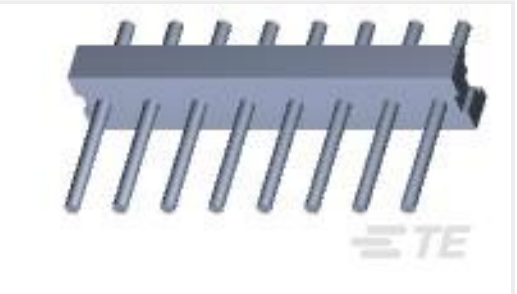

TE Part #3-641203-8
08P MTA156 HDR ASSY PL 30AU LF



TE Part #1-2176049-8
RLP73N 1E R27 1% 1K RL

Documents

Product Drawings

07P MTA100 HDR ASSY,NARROW AU

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_644884-7_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_644884-7_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_644884-7_C.3d_stp.zip

English

Customer View Model

ENG_CVM_644884-7_A.3d_igs.zip

English



Customer View Model

[ENG_CVM_644884-7_A.3d_stp.zip](#)

English

3D PDF

English

Customer View Model

[ENG_CVM_644884-7_A.2d_dxf.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Product Specification](#)

English

Agency Approvals

[Agency Approval Document](#)

English