


 
PLIO® DO oval grommets in flexible PVC

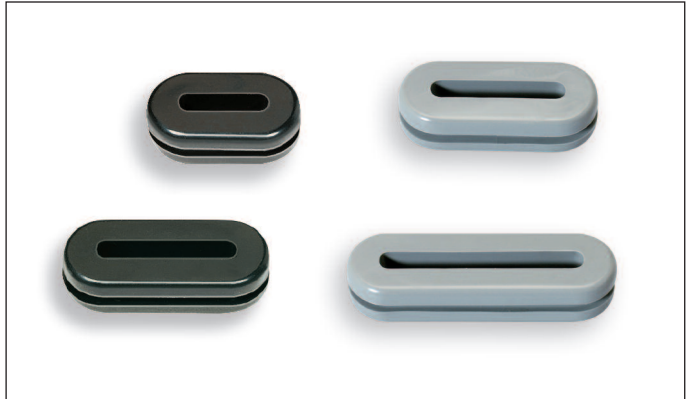

DO-PVC

Material:	flexible PVC
Colours:	black - grey
Temperature range:	-30 to +70°C
Hardness Shore A:	55 ± 5
Tensile strength at break:	10 MPa
Ultimate elongation:	350 %
Dielectric strength:	> 20 kV/mm
Specification:	HB UL94
Application:	for flat wire protection.



type	article number		
	black 010	grey 013	
DO-PVC 19/27/33/3	0135 0001 010	0135 0001 013	100
DO-PVC 29/37/43/3	0135 0002 010	0135 0002 013	100
DO-PVC 44/52/58/3	0135 0003 010	0135 0003 013	100

If no colour is mentioned on the order, DO grommets will be supplied in grey.

