

# EMG728

## Cut level B / A2 cut resistant glove with nitrile sandy coating

A soft and comfortable light cut resistant glove with sandy nitrile coating. Ideal for handling sharp parts in dry , oily or greasy conditions.

### Features

- ▲ Glass and steel fibre free reduce risks of irritation
- ▲ Durable sandy nitrile palm coating ensures good protection against abrasion and excellent grip in wet/oily environments
- ▲ Contact heat protection up to 100°C / 212°F for a short period (15 sec max)
- ▲ Reinforced thumb crotch enhances durability
- ▲ Breathable back of hand to reduce perspiration
- ▲ Seamless knit prevents irritation



### Certifications



### Suitable industries & applications

#### Industries

- ▲ Aerospace
- ▲ Automotive

- ▲ Construction

#### Applications

- ▲ Component and Product Assembly
- ▲ General Goods Handling
- ▲ Woodwork and Fabrication
- ▲ General Maintenance

#### Europe

sales@globus.com  
+44 (0)161 877 4747  
+44 (0)161 877 4746

#### Middle East & Africa

sales.gcc@globusgroup.com  
+971 4 882 9962  
+971 4 882 9963

#### Americas

salesusa@globusgroup.com  
+1 83 337 54747

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment. The manufacturer reserves the right to make any modifications it deems necessary.

# EMG728

Cut level B / A2 cut resistant glove with nitrile sandy coating

## Product information

|                   |                        |                      |
|-------------------|------------------------|----------------------|
| <b>Materials</b>  | Liner:                 | 13 Gauge HPPE, Nylon |
|                   | Coating:               | Sandy Nitrile        |
| <b>Colour</b>     | Grey / Black           |                      |
| <b>Length</b>     | 260mm                  |                      |
| <b>Cuff Style</b> | Elasticated Knit Wrist |                      |

## Ordering information

|             |            |                               |
|-------------|------------|-------------------------------|
| <b>XS</b>   | EMG00728FB | Items per Pack<br>10 x Pairs  |
| <b>S</b>    | EMG00728FD |                               |
| <b>M</b>    | EMG00728FF | Items per Case<br>120 x Pairs |
| <b>L</b>    | EMG00728FH |                               |
| <b>XL</b>   | EMG00728FJ |                               |
| <b>XXL</b>  | EMG00728FL |                               |
| <b>XXXL</b> | EMG00728FN |                               |


## Additional information

Certification legend



or click [here](#)

Declaration of conformity

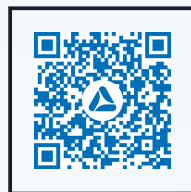

or click [here](#)

View product online



or click [here](#)

### Europe

sales@globus.com  
+44 (0)161 877 4747  
+44 (0)161 877 4746

### Middle East & Africa

sales.gcc@globusgroup.com  
+971 4 882 9962  
+971 4 882 9963

### Americas

salesusa@globusgroup.com  
+1 83 337 54747

**Globus Group**, T2 Trafford Point, Twining Road, Trafford Park, Manchester, M17 1SH, UNITED KINGDOM  
**Globus EMEA FZE**, Jafza One, Tower A, Office 2201, Jebel Ali, PO Box 61195, Dubai, UNITED ARAB EMIRATES  
**Globus Americas LLC**, 45 Rockefeller Plaza, Suite 2000, New York City, New York, 10111, USA

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment.  
The manufacturer reserves the right to make any modifications it deems necessary.