
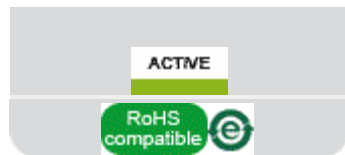


10073599-010LF - Minitek™  
: Active Latch Housing,  
Double Row, 10 Position

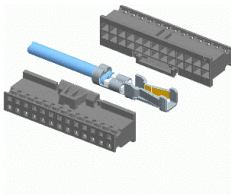

[www.fci.com](http://www.fci.com)

## Mating Half

10075025-G01-10ULF

## Specifications

General	
Number of contacts (Total)	10
Number of rows	2
Product Type	Active Latch Housing
Mating half	Mates with 0.5 (0.02 in.) Square Pin. Mating Pin Length of 3.63 to 4 mm (0.143 to 0.157 in.)
Electrical	
Withstanding Voltage	650V rms
Current rating	2 amp Continuous
Resistance (Insulation)	1000 M ohms min
Mechanical	
Durability (Mating cycles)	50
Physical	
Color (Housing)	Black
Material (Housing)	Thermoplastic
Temperature (Operating - range)	-55°C to +125°C
Approvals / Certifications	
UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved
Other Features	
Packaging (Type)	Bag