



SIVACON, door, right, inspection window, IP55, H: 1800 mm, W: 900 mm, RAL 7035, protection class 1

Model		
product brand name		SIVACON
product designation		Door
design of the product		Inspection window
design of the surface		Powder-coated
design of the product EMC version		No
Protection class		
protection class IP		IP55
operating resource protection class		safety class 1
Appearance		
RAL color number		7035
color		light grey
Product details		
product component		
• ventilation		
• viewing door		
• door for disconnecter lock		
Mechanical Design		
height		1 800 mm
width		900 mm
opening direction of the door		right
net weight		21 kg
material		Steel/glass
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

[Miscellaneous](#)

Environment

Siemens
EcoTech



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1890-2UT14-0BE2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1890-2UT14-0BE2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1890-2UT14-0BE2

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

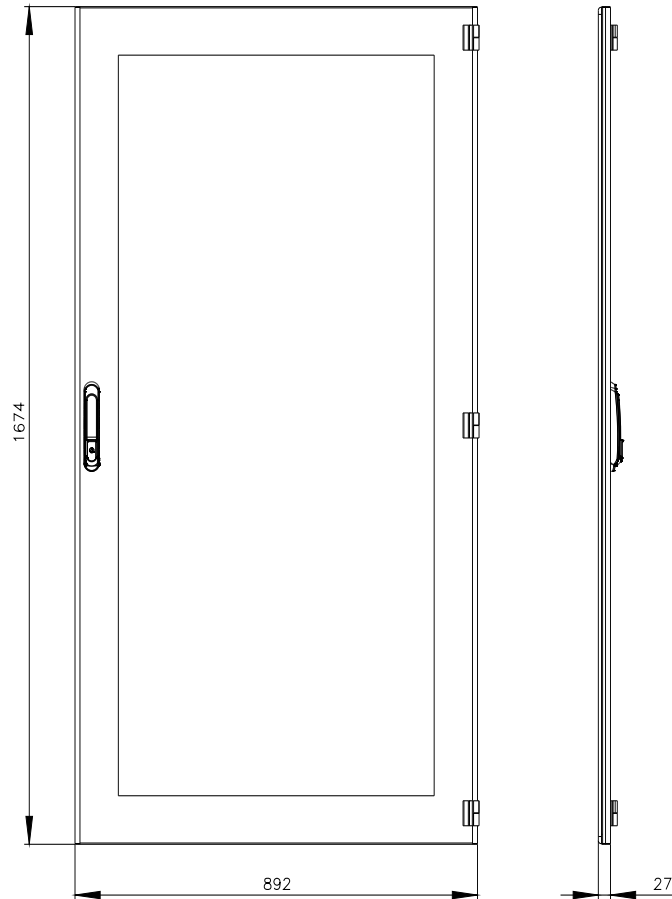

last modified:

4/13/2025 

