



Brand of NTN corporation

Technical data

UKFLE206H

Bearing units




Grey cast housing, radial insert ball bearing with adapter sleeve, seal with slinger.
Deviation from figure: For some sizes, the bearing inserts may protrude beyond the mounting surface of the housing.

KIT CONTENT

UK206G2H, FLE206

VISUAL (S)

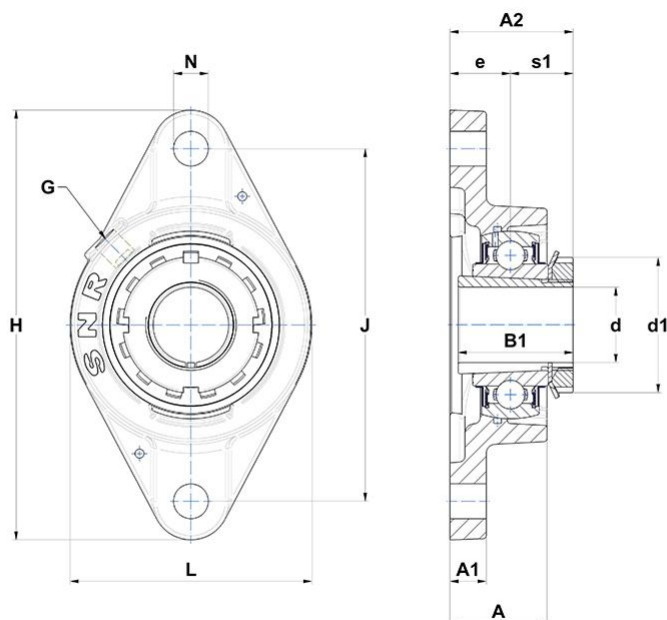

PRODUCT DEFINITION

Brand	SNR
A - Housing height	32,1 mm
A1 - Housing foot height / flange height	12 mm
A2 - Total height from mounting surface	40,5 mm
B - Width of Inner Ring	25 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

B1 - Overall width Inner Ring	38 mm
d - Shaft diameter	25 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	45 mm
e - Distance mounting surface to bearing center	20 mm
G - Grease fitting	R1/8"
H - Housing length, width or diameter	142 mm
J - Mounting holes distance	116,5 mm
L - Housing width / diameter	80 mm
N - Mounting hole dimension	11,5 mm
s1 - Distance nut to middle of bearing raceway	20,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	19500000 mN
C0 - Static load rating	11200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,87 kg
Adapter sleeve designation	H2306

