

Datasheet

RS PRO VINYL-INSULATED FLANGE SPADE

TERMINALS

Stock number: 178-8359

MAXIMUM ELECTRIC CURRENT:

A.W.G.	16	14
AMP.	18	30


MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

TERMINAL MATERIAL: COPPER

INSULATION COLOR: BLUE

TERMINAL BARREL I.D.: D1=2.3MM

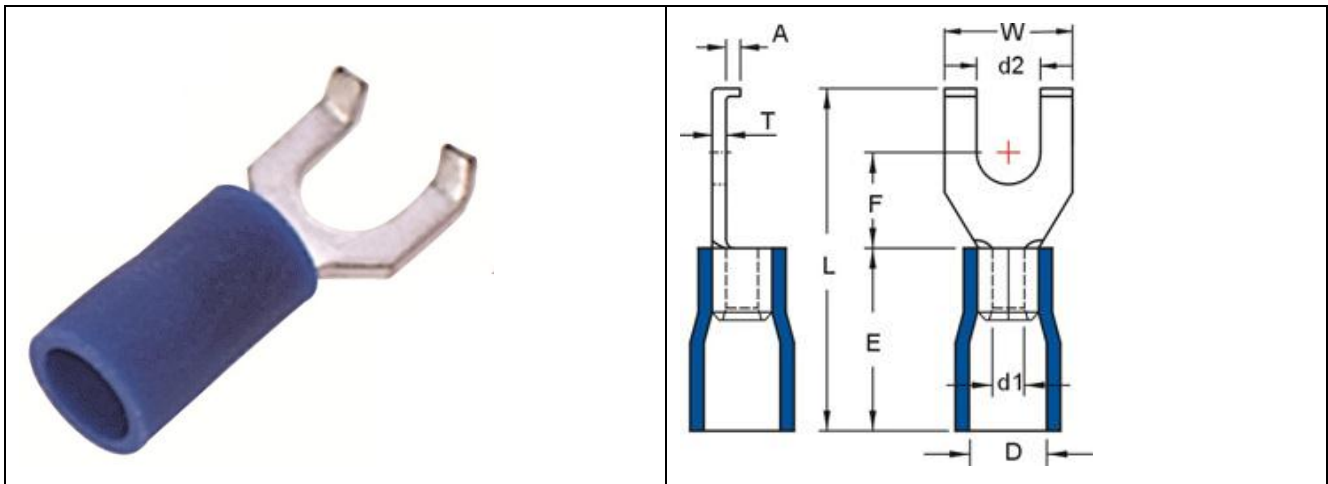

WIRE RANGE A.W.G. mm ²	ITEM NO. BUTTED SEAM	STUD SIZE d2	DIMENSION inch(mm)								
			W	F	L	E	D	d1	A	T	
16-14 A.W.G.	178-8359	#8	0.169	0.295	0.205	0.768	0.394	0.177	0.091	0.059	0.31
1.5-2.5 mm ²			4.3	7.5	5.2	19.5	10	4.500	2.3	1.5	0.8