


Geberit Mapress Copper T-piece, reduced (gas)



Example image

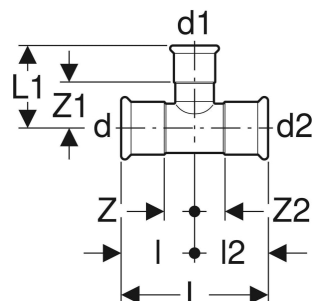

APPLICATION PURPOSES

- For natural gases
- For liquefied gases
- For natural and liquefied gases

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Marked in yellow
- Seal ring made of HNBR, yellow

- Pressing socket with yellow protection plug

TECHNICAL DATA

Product material Cu-DHP copper CW024A (EN 1412)

Art. no.	DN	d, ø mm	d1, ø mm	d2, ø mm	arc °	L cm	L1 cm	I cm	I2 cm	Z cm	Z1 cm	Z2 cm
34535	15 / 12 / 15	18	15	18	90	6.8	3.5	3.4	3.4	1.4	1.5	1.4
34553	20 / 12 / 12	22	15	15	90	8	3.8	3.7	4.3	1.6	1.8	2.3
34536	20 / 12 / 20	22	15	22	90	7.4	3.8	3.7	3.7	1.6	1.8	1.6
34537	20 / 15 / 20	22	18	22	90	7.4	3.8	3.7	3.7	1.6	1.8	1.6
34554	20 / 20 / 12	22	22	15	90	8.3	3.7	3.7	4.6	1.6	1.6	2.6

Art. no.	DN	d, ø mm	d1, ø mm	d2, ø mm	arc °	L cm	L1 cm	l cm	l2 cm	z cm	z1 cm	z2 cm
34588	25 / 12 / 25	28	15	28	90	8.4	4.1	4.2	4.2	1.9	2.1	1.9
34589	25 / 15 / 25	28	18	28	90	8.4	4.1	4.2	4.2	1.9	2.1	1.9
34590	25 / 20 / 25	28	22	28	90	8.4	4.1	4.2	4.2	1.9	2	1.9
34543	32 / 20 / 32	35	22	35	90	10	5.2	5	5	2.4	3.1	2.4
34544	32 / 25 / 32	35	28	35	90	10	5.5	5	5	2.4	3.2	2.4
34545	40 / 20 / 40	42	22	42	90	11.4	5.5	5.7	5.7	2.7	3.4	2.7
34546	40 / 25 / 40	42	28	42	90	11.4	5.8	5.7	5.7	2.7	3.5	2.7
34547	40 / 32 / 40	42	35	42	90	11.4	6.2	5.7	5.7	2.7	3.6	2.7
34548	50 / 20 / 50	54	22	54	90	13.8	6.1	6.9	6.9	3.4	4	3.4
34549	50 / 25 / 50	54	28	54	90	13.8	6.4	6.9	6.9	3.4	4.1	3.4
34550	50 / 32 / 50	54	35	54	90	13.8	6.8	6.9	6.9	3.4	4.2	3.4
34551	50 / 40 / 50	54	42	54	90	13.8	7.2	6.9	6.9	3.4	4.2	3.4