

Product data sheet

Specifications



Photoelectric sensors XU, XUA, emitter, 12...24 VDC, M8

XUAH0203S

Product availability : Stock - Normally stocked in distribution facility

Price* : 107.00 USD

Main

Range of Product	Telemecanique Photoelectric sensors XU
Series name	Application assembly
Electronic sensor type	Photo-electric sensor transmitter
Sensor name	XUA
Sensor design	Cylindrical M8
Detection system	Thru beam
Material	Metal
Line of sight type	Axial
Supply circuit type	DC
Wiring Technique	3-wire
Electrical connection	1 male connector M8, 3 pins
Emission	Infrared thru beam
[Sn] nominal sensing distance	6.56 ft (2 m) thru beam need a receiver

Complementary

Enclosure Material	Nickel Plated Brass
Lens material	PMMA
Add on input	Test by emission breaking
[Us] rated supply voltage	12...24 V DC reverse polarity protection
Supply voltage limits	10...30 V DC
Current consumption	<= 15 mA
Maximum delay first up	20 ms
Setting-up	Without sensitivity adjustment
Diameter	0.31 in (8 mm)
Length	1.85 in (47 mm)
Net Weight	0.03 lb(US) (0.015 kg)

Environment

Product Certifications	CE
------------------------	----

* Price is “List Price” and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

	cULus
Ambient Air Temperature for Operation	-13...131 °F (-25...55 °C)
Ambient Air Temperature for Storage	-22...158 °F (-30...70 °C)
Vibration resistance	7 gn +/- 1 mm 10...55 Hz) IEC 60068-2-6
Shock resistance	30 gn 11 ms) IEC 60068-2-27
IP degree of protection	IP65 IEC 60529

Ordering and shipping details

Category	22481-SENSORS, PHOTOELECTRIC
Discount Schedule	DS2
GTIN	3389110427158
Nbr. of units in pkg.	1
Package weight(Lbs)	1.09 oz (31.0 g)
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	1.69 in (4.3 cm)
Package 1 width	2.56 in (6.5 cm)
Package 1 Length	3.74 in (9.5 cm)
Unit Type of Package 2	S01
Number of Units in Package 2	24
Package 2 Weight	31.25 oz (886.0 g)
Package 2 Height	5.91 in (15 cm)
Package 2 width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)


Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------


Dimensions

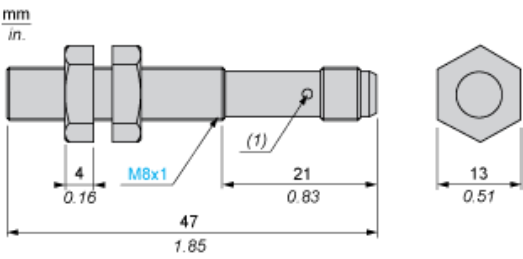

(1) LED, 4 viewing ports at 90°
Note : Fixing nut tightening torque : <2N.m


Wiring Schemes

M8 Connector

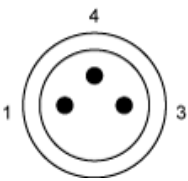


- 1 : (+)
- 3 : (-)
- 4 : OUT or test

Transmitter

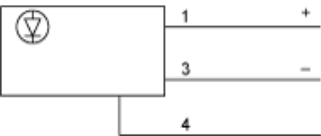


Beam Break Test

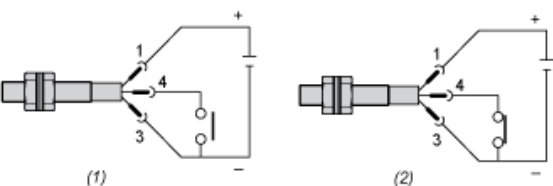


- (1) Beam made LED on (steady light)
- (2) Beam broken LED flashing

Detection Curves

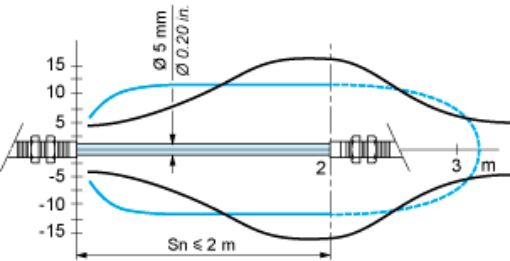

Excess Gain Curves (Ambient temperature: ± 25 °C)

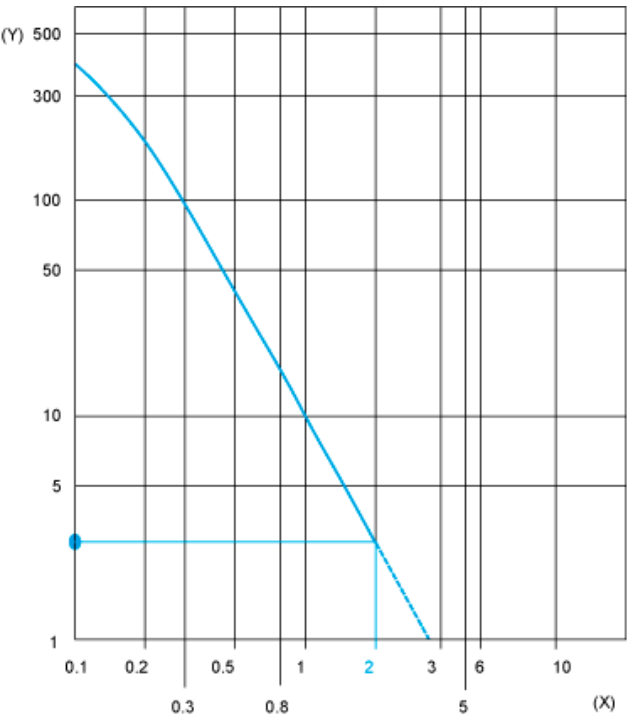

(Y)

Gain

(X)

Distance (m)