




Product data sheet

Power tools for trade & industry

Table Saw

PRO GTS 70-216

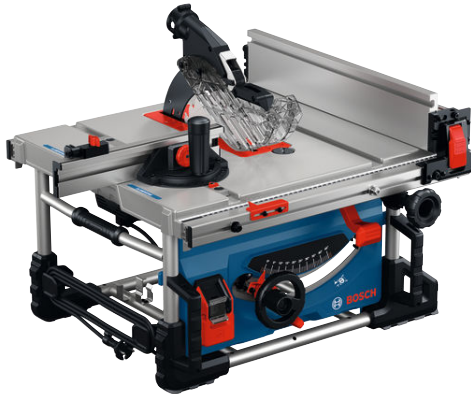

Compact table saw with best-in-class cutting height

The most important data

Saw blade diameter	216 mm
Incline setting	47 ° L / -2 ° R
Table size	593 x 494 mm

Part Number 0 601 B30 670

Technical data

Technical data

Rated input power	1,850 W
Table size	593 x 494 mm
Tool dimensions (width x length x height)	608 x 593 x 329 mm
No-load speed	5,500 rpm
Saw blade diameter	216 mm
Cutting height 90°	70 mm
Cutting height 45°	49 mm
Saw blade bore diameter	30 mm
Incline setting	47 ° L / -2 ° R
Weight	22.3 kg
Max. cutting capacity on the right	635 mm
Max. cutting capacity on the left	305 mm
Packaging dimensions (width x length x height)	655 x 665 x 380 mm

**BOSCH**

Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- Highly portable thanks to compact design with best-in-class cutting height of 70 mm
- Ensures precision cutting thanks to rack & pinion rip fence system and precise miter gauge
- Minimizes dust with two Click & Clean dust ports
- Convenient clampzone areas to fix workpieces to the tabletop

**HEAVY
DUTY**

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/gb/en/wac/>

