
 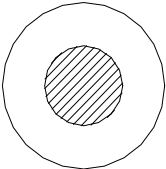





Datasheet

Product Name:	UL1429 22AWG
Product Discription:	UL1429 22AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	150V	Conductor	Stranded Tinned Copper		
Rated Temperature:	80°C	Size(AWG)	22		
Reference Standard:	UL758,UL1581	Construction(±0.008mm)	7/0.254		
Cross Section		Stranded Dia.(mm)Ref.	0.76		
		Insulation Material	XLPVC		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.23		
		Insulation Dia.(±0.06mm)	1.28		

Marking	Remark:
E148000  AWM STYLE 1429 22AWG 80°C 150V VW-1 ---	8775355 Red 8775364 Blue 8775377 Grey 8775386 Violet
C  AWM I A 80°C 150V FT1 -F- -LF- PC10 LTK	8775358 Black 8775367 White 8775370 Yellow
	8775351 Brown 8775361 Green 8775373 Orange

Applications					Characteristics		Customer Approve
For Internal Wiring of Appliances or Electronic Equipment					Test Item	Standard Value	Seal & Stamp
					Test Material	XLPVC(ROHS)	
					Insulation DC resistance(MΩ*km)	10	
					Vol. Tesr(AC.V.60S) (V)	2000	
					Flammability Test	VW-1	
Revisions					Max.DC Resistance(20°C Ω/km)	59.4(MAX)	Signature: Date:
Version	Description	Drawn by	Approved by	Date			
0	New document issue	Lisa	Jason	18/05/2015			