



AMP Connect

Alphabetical **SEARCH** Picture **SEARCH** Part Number **SEARCH**

[Go To Step Search™ Screen](#)

**320568 -- 1 of 1 products**


Terminals and Splices

Ring and Spade Tongue Terminals

General **INFO**

Sales **INFO**

Customer Drawings **SPECIFICATIONS**

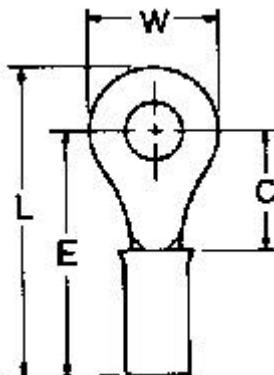

*Line art represents typical product only.*

## ***Searchable Features:***

<b>Terminal Shape</b>	Ring Tongue
<b>Body Style</b>	PIDG
<b>Receptacle Style</b>	Straight
<b>Barrel Type</b>	Closed Barrel
<b>Wire/Cable Type</b>	Regular Wire
<b>Wire Range</b>	12-10 [2.62-6.64 <sup>2</sup> ] AWG [mm]
<b>Wire Range (CMA)</b>	5,180-13,100
<b>Insulation</b>	Yes
<b>Insulation Support</b>	Insulation Support
<b>Insulation Diameter</b>	.230 [5.84] Max. in. [mm]
<b>Stud Size</b>	8 [M4]
<b>Stud Diameter</b>	.164 [4.16] in. [mm]
<b>Shape</b>	RING-041
<b>Heavy Duty</b>	Standard
<b>Packaging Method</b>	Loose Piece
<b>Material</b>	Copper
<b>Finish</b>	Tin

## ***Other Properties:***

<b>Dim. C</b>	.302 [7.67] Min. in. [mm]
<b>Dim. E</b>	.893 [22.68] Max. in. [mm]
<b>Dim. L</b>	1.083 [27.51] Max. in. [mm]
<b>Dim. W</b>	.375 [9.53] in. [mm]
<b>Tongue Material Thickness</b>	.042 [1.07] Max. in. [mm]
<b>Color</b>	Yellow
<b>CERTI-CRIMP Hand Tool</b>	59239-4, 525692-0 (Great Britain Tool)
<b>CERTI-LOK Hand Tool Frame Assembly</b>	169400
<b>CERTI-LOK Die Assembly</b>	169404
<b>Comment</b>	"C" dimension applies from edge of metal wire barrel to center of stud hole. Available On-Tape for Automatic Termination.