


> 32W1533DB

TOSHIBA

Leading Innovation >>>

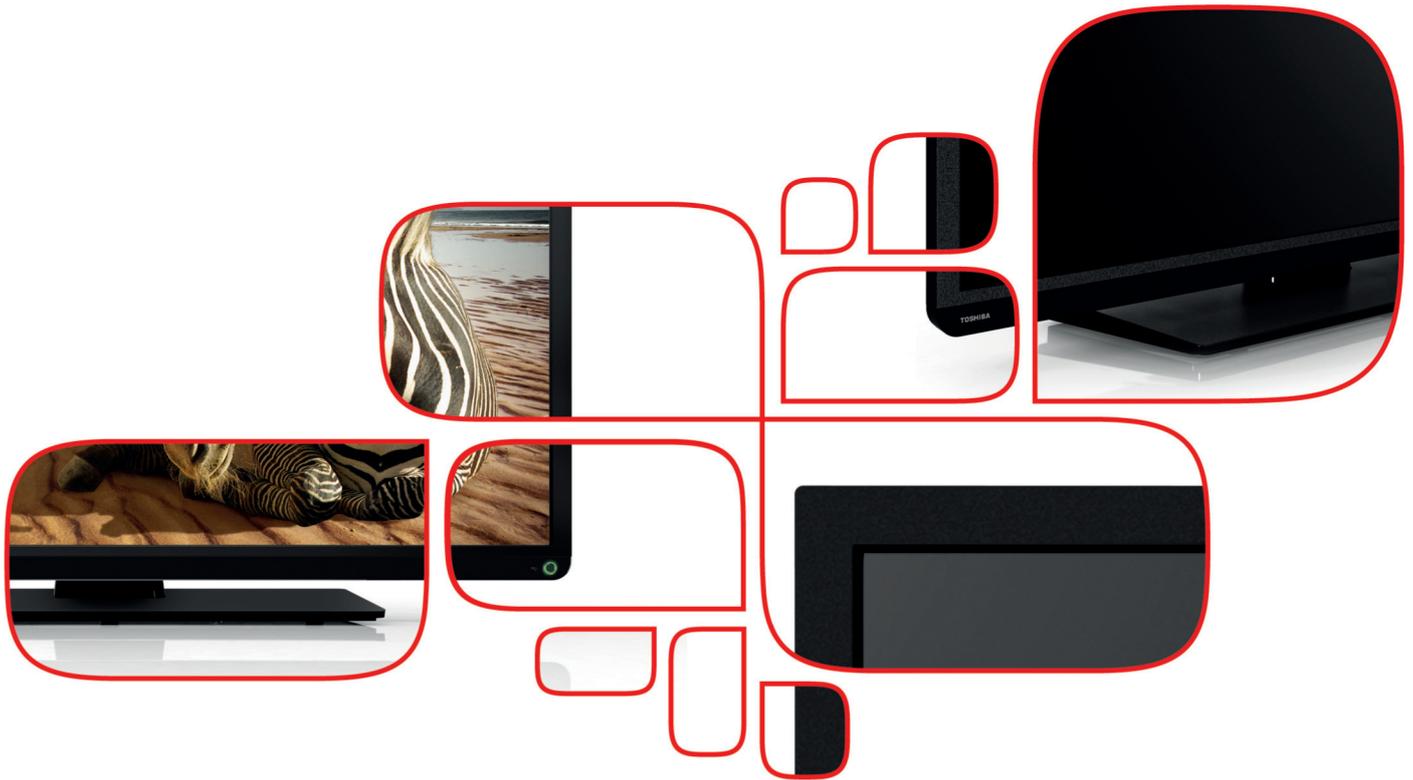

WELCOME TO THE WORLD OF HD

If you're looking for your first High Definition TV, or a screen that will blend beautifully into any room in the house, the new Toshiba W1 series is an ideal choice.

It packs a crystal-clear LED display and the latest TV features into a slim, elegantly crafted black or white design. So whether you want movies in the bedroom, sports in the kitchen or just a compact, affordable HD experience, the W1 series delivers. The built-in Dual Tuner opens up the world of digital TV but the W1 series does much more than that. View pictures and home movies by plugging a USB stick or HDD into the USB port or connect consoles or DVD and Blu-ray players by HDMI to enjoy games and movies in full-impact High Definition.

Whatever you decide to do with the new W1 series, you can be sure that this stylish TV won't let you down.



LED TV

Latest LED technology combines slim designs, brilliant colours and high energy efficiency.

HD ready

HD Ready 720p resolution displays High Definition images from any HD source.

DUAL TUNER

Built-in digital tuner to access all your favourite digital channels without extra equipment.

TECHNICAL SPECIFICATIONS

Picture

Diagonal Screen Size (cm)	80
Diagonal Screen Size (inch)	32
Visible Area (H x V)	698 x 392
Screen Format	16:9
Panel Resolution	1366 x 768
Brightness (cd/m ²)	300
Response Time (G to G) (ms)	20
Viewing Angle (°)	178
HD TV	Yes
50Hz	Yes
AMR+	100
Digital Noise Reduction	Yes
Active Backlight Control	Yes
Colour Temperature selectable	Yes
Manual picture size select	Yes
Native Contrast (number)	4000
LED Direct	Yes
Native Contrast	Yes
Contrast (Ultra, Mega, High)	High
Dynamic Contrast	Yes
Dynamic Contrast (number)	22000

Interactive Features

Digital Text	Yes
Text Page Memory	1000 Channels
Electronic Programme Guide 8 Day	8 Days

Audio

NICAM Stereo	Yes
Dolby® Digital Plus	Yes
Sound Output (RMS) W	2X6W

Accessories (included in carton box)

Remote Control (Type)	CT-8046
Remote Control Battery	(AAA) x 2
TV Stand Separate	Yes
Instruction Manual (QSUG)	Yes
3.5mm Composite Adapter	Yes

Cabinet

Colour	Mat black bezel with black trim and slant mold black stand
--------	--

Dimensions

Width (mm)	736
Height without stand (mm)	452
Height with stand (mm)	487
Depth without stand (mm) - Minimum point	25
Stand depth (mm)	230
Packed width (mm)	795
Packed depth (mm)	165
Packed height (mm)	585
VESA - W x H (screw type)	200 x 100 (M4)

Eco

Energy Label	A+
Presence of Lead (Below RoHS Directive limit including exemptions)	Yes

Mercury Content	< 0.1 mg/kg
Peak Luminance	85

Power Supply

Power Consumption EN62087 - Home Mode (W)	30.0
Power Consumption EN60065 - Maximum power (W)	65
Power Consumption - Stand-by (W)	0.30
Yearly Energy Consumption (average kWh)	43
Line Voltage	220-240V/50Hz

Connections

Number of HDMI® (back)	2
2160p, 1080p, 1080i, 720p, 720i, 576p, 576i, 480p, 480i	1080p, 1080i, 720p, 720i, 576p, 576i, 480p, 480i
24Hz (24p)	Yes
Component Video	Yes (via VGA)
Composite Video	Yes (3mm jack)
3.5mm Composite Adapter	Yes
SCART	1 (FULL RGB)
S-Video	Yes via SCART
Analogue audio (Cinch) Audio (mini jack)	NO (via Side AV)
PC Input	Yes
Number of USB	1
Digital Audio Out	Yes (Coax)
Headphone	Yes

Tuning

TV Standards	PAL BG/I/DK SECAM BG/DK/L NTSC BG 4.43
Number of Channels	800
Analogue	Yes
DVB-T	Yes
DVB-C / DVB-C (HD)	Yes
H.264	Yes
NTSC Video-Playback	Yes
Auto Set-up	Yes
DVB Common Interface+ (CI+) v1.2	Yes

USB Features

Picture (USB)	JPEG Base / JPEG Progressive, BMP
Audio (USB)	MPEG1 layer 2 MP3, MPEG1 layer 3 MP3, AC3, ASF, LPCM*, IMA-ADPCM/MS-ADPCM*, LBR** video files only
Video (USB)	MPEG1 layer 2 MP3, MPEG1 layer 3 MP3, AC3, ASF, LPCM*, IMA-ADPCM/MS-ADPCM*, LBR** video files only