

Datasheet

Compact EI Transformers SI-DIN 35 RS Pro

The standard moulded 1 phase EI transformers with integrated screw terminals and DIN rail TS35 mount designed according to the following specifications.

- Designed for continuous load
- 3-module enclosure
- High quality safety and isolating transformers designed for use in general applications. It could be also use for; bells, gongs and door openers.
- Standard primary winding 230VAC
- Detailed product specification on permanent label.
- High efficiency, low regulation design
- 100% electrical and flash tested
- Thermal protection 100° C
- Protected against short circuit





Specifications






Power:	8 - 20 VA
Frequency:	50/60 Hz
Primary:	230 VAC
Secondary:	2x4V, 8V, 2x12V
Isolation:	4 kV RMS
Temp. class:	B (130°)
Standard:	EN61558-2-6



Dimensions in (mm):

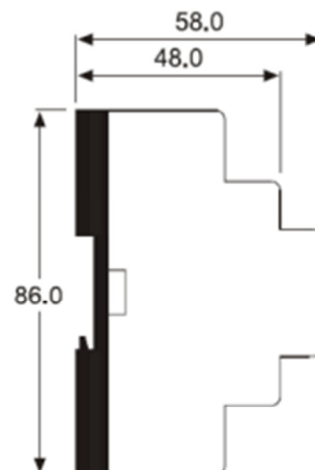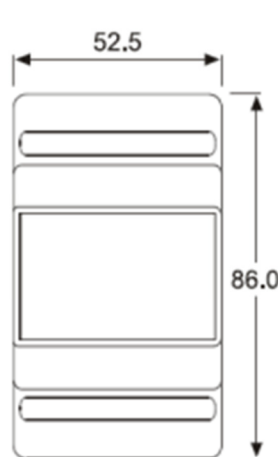

Schematics:

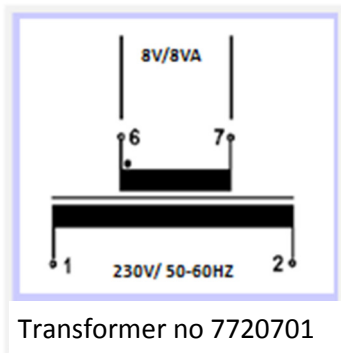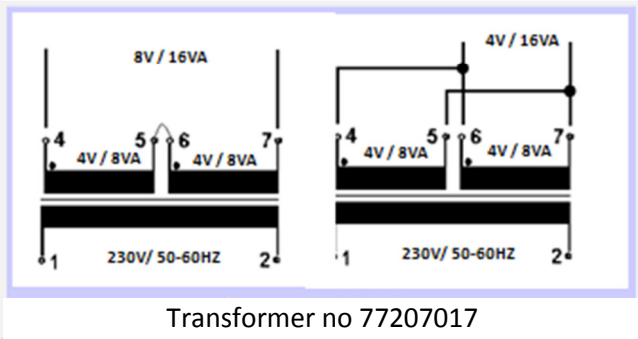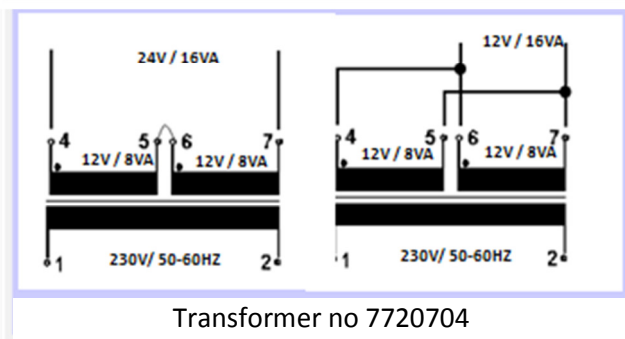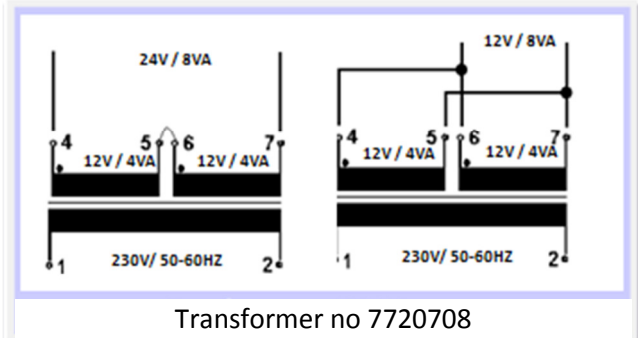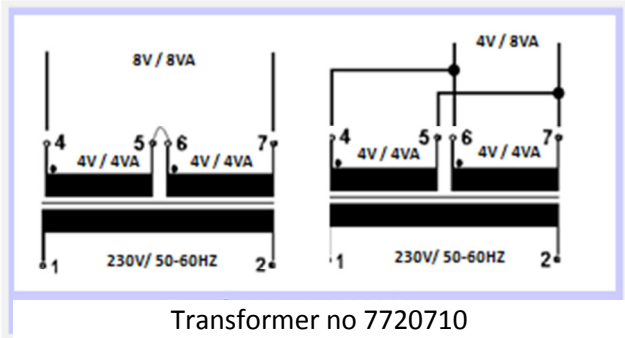

Ordering details:

RS Stock number	Power [VA]	Description	Secondary [V]
7720710	8	Compact EI Transformers SI-DIN 35	2 x 4
7720708	8	Compact EI Transformers SI-DIN 35	2 x 12
7720701	8	Compact EI Transformers SI-DIN 35	2 x 8
7720717	16	Compact EI Transformers SI-DIN 35	2 x 4
7720704	16	Compact EI Transformers SI-DIN 35	2 x 12