


Grey Elastic Rubber Trolley Wheel 160mm, 350kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **58-516-160R20**

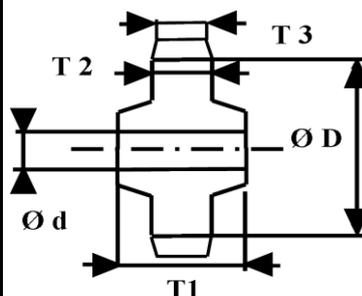

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, grey bonded elastic rubber tyre, non marking.
 Hub : symmetrical, roller bearing.

Specifications

Wheel Diameter - ØD ± 1%	160 mm
Hub Type	Roller Bearing
Hub Length T1	60 mm ±1
Width of Tread T2	48 mm ±1
Width of Tread-on floor T3	48 mm ±1
Axle Hole Ø d	Ø 20 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	350 Kg
Temperature	-20 / +60 °C
Weight	0,75 Kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduces shock and vibration.
 Quiet in use and high wear resistance.
 Suitable for industrial floors and also all interior floors.