

87190

Extra thin natural rubber glove for excellent sensitivity

Previously known as: Econohands™ 87-190

## Extra-thin natural latex rubber gloves, offering excellent tactile sensitivity for light-duty tasks

- Heightened tactile sensitivity:** With just 0.35mm/18.8 mil thickness, AlphaTec® 87-190 natural rubber latex work gloves are extra-thin, resulting in excellent tactile sensitivity
- Elevated comfort:** These high-dexterity work gloves also feature pure cotton flock lining, which absorbs sweat and makes sustained wear more comfortable
- Reduced allergy risks:** Thanks to a special chlorination treatment, these light-duty AlphaTec® industrial gloves are also less likely to cause an allergic reaction

### Industries

- Automotive Aftermarket
- Chemical
- Construction
- Metal fabrication
- Maintenance

### Applications

- Cleaning
- Assembly of parts
- Maintenance



Previously known as: Econohands™ 87-190

### Key Features


- **0.35mm/18.8 mil thickness:** Superb sensitivity levels
- **100% cotton flock lining:** Reduced sweat, greater comfort
- **Chlorination treatment:** Allergic reactions minimized

### Vulcanization Chemical Accelerators

- Natural rubber proteins
- Zinc Diethyldithiocarbamate

Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.

### Performance Standards

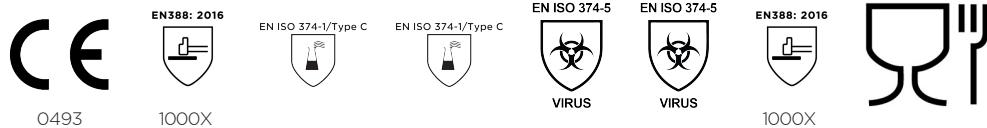

### Specifications

BRAND   STYLE	DESCRIPTION	SIZE	LENGTH	COLOR	PACKAGE
AlphaTec® 87-190	<b>Liner Material:</b> Cotton Flocking <b>Coating Material:</b> Natural Rubber Latex	6.5, 7.5, 8.5, 9.5	305 / 12	Yellow	• 12 pairs per bag, 12 bags per carton

**Europe, Middle East & Africa Region**  
 Ansell Healthcare Europe NV  
 Riverside Business Park  
 Blvd International, 55  
 1070 Brussels, Belgium  
 T: +32 (0) 2 528 74 00  
 F: +32 (0) 2 528 74 01

**North America Region**  
 Ansell Healthcare Products LLC  
 111 Wood Avenue South,  
 Suite 210  
 Iselin, NJ 08830, USA  
 T: +1 800 800 0444  
 F: +1 800 800 0445

**Latin America & Caribbean Region**  
 Ansell Commercial Mexico S.A. de C.V.  
 Blvd. Bernardo Quintana No. 7001-C,  
 Q7001 Torre II,  
 Suites 1304, 1305 y 1306.  
 Col. Centro Sur, c.p. 76079  
 Queretaro, Qro. Mexico  
 T: +52 442 248 1544 / 248 3133

**Canada**  
 Ansell Canada Inc.  
 105, rue Lauder  
 Cowansville (Québec)  
 J2K 2K8, Canada  
 T: 1800 363-8340  
 F: 1888 267-3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:  
[www.ansell.com/patentmarking](http://www.ansell.com/patentmarking) © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.