


## Technical data sheet

### Article number:

**118-00034**

**T18ROS**

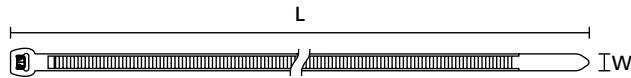

|                                    |  |
|------------------------------------|--|
| <b>Product Group</b>               | Cable ties for thin-walled bundles                                 |
| <b>Product Family</b>              | OS-Series  |
| <b>Material</b>                    | Polyamide 6.6, heat stabilised (PA66HS)                            |
| <b>Colour</b>                      | Natural (NA)   |
| <b>Application Range</b>           | Indoor Use   |
| <b>Application Tool</b>            | MK3PNP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7ISP |
| <b>Bundle Ø max.</b>               | 20.0 mm  |
| <b>Bundle Ø min.</b>               | 1.6 mm   |
| <b>Flammability</b>                | UL 94 V2   |
| <b>Halogen-free</b>                | Yes  |
| <b>Height (H)</b>                  | 1 mm   |
| <b>Length (L)</b>                  | 100 mm   |
| <b>Min.Tensile Strength</b>        | 80 N   |
| <b>Operating Temperature</b>       | -40 °C to +105 °C  |
| <b>Package Content</b>             | 200 pcs.   |
| <b>Package Content packed in</b>   | bag  |
| <b>Releasable Closure (Yes/No)</b> | No   |
| <b>Thickness (T)</b>               | 1.0 mm   |
| <b>Toothing (Serration)</b>        | Outside Serrated   |
| <b>Variant</b>                     | Outside Serrated   |
| <b>Width (W)</b>                   | 2.5 mm   |

