




ENGLISH

Datasheet

Stock No: 522-620

RS Pro SY Control Cable, 4 Core, Polyvinyl Chloride PVC Sheath

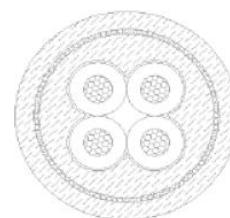

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 32$

Insulation: PVC

Insulation Dia. (mm): $2.52 \pm 0.1 \times 4C$

Filler: Chalk

Jacket 1: PVC

Outer Dia. (mm): 7.0 ± 0.2

Braid Shield: Galvanised Steel

Conductor Dia. (mm): 0.24

Conductor Qty: 24 x 4

Jacket: Trans PVC

Outer Dia. (mm): 10.08 ± 0.25

Colour:

The colour of the insulation: Blue , Brown ,
Black ,

Yellow/Green

The jacket colour: Transparent

Marking(3times/m):

RS 522620 SY/CC 4 Core x

1.0mm²

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):300

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<21.1

Min.Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 10 A