
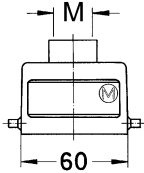
 

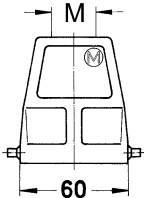
 

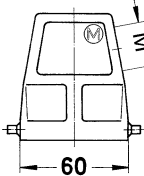
 

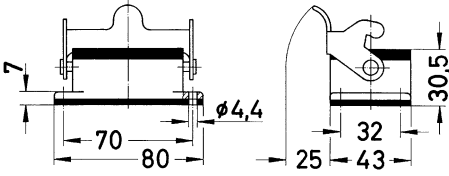
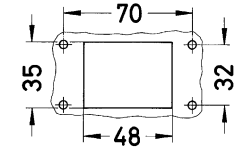


Hoods/housings for more demanding environmental requirements
Single locking lever

Identification	Cable entry	Part number		Drawing (dimensions in mm)	
		Low construction	High construction		
Han® M , Hoods, Top entry 	1x M20 1x M25 1x M32	19 37 006 1440	19 37 006 0445 19 37 006 0446 19 37 006 0447		
Han® M , Hoods, Side entry 	1x M20 1x M25	19 37 006 1540	19 37 006 0545 19 37 006 0546		
Han® M , Hoods, Side entry 	1x M20 1x M25	19 37 006 1540	19 37 006 0545 19 37 006 0546		
Housings Han® M , Bulkhead mounted housings 		09 37 006 0301			 <p>Panel cut out</p>