


Products compliant with Electrical Appliance and Material Safety Law(Unit : mm)


Model No. : 489-008-L10/489-008-L21/489-008-L35

For 80×80×42mm

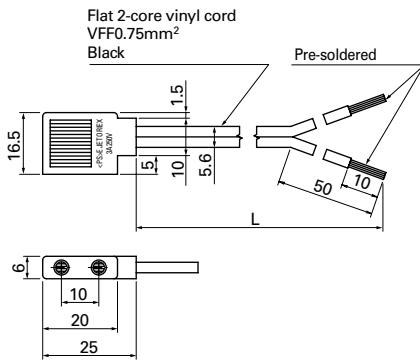


Model No. : 489-016-L10/489-016-L21

For 120×120×25mm  
92×92×25mm  
80×80×25mm  
80×80×38mm

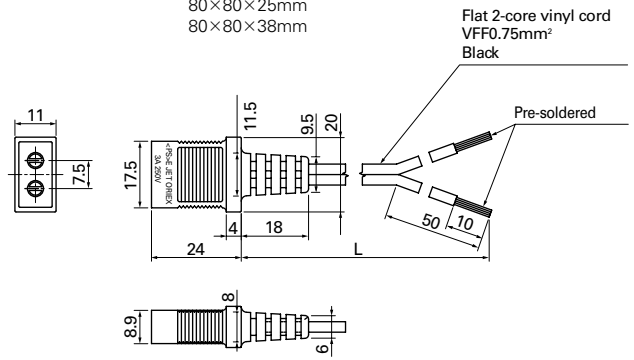


Model No. : 489-006-L10/489-006-L21/489-006-L35

For 120×120×38mm

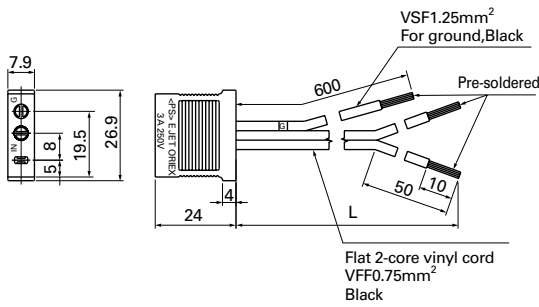


Model No. : 489-037-L10/489-037-L21/489-037-L35

For 120×120×38mm

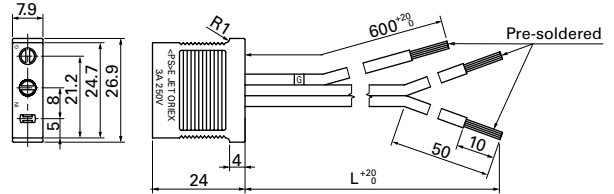


Model No. : 489-1618-L10/489-1618-L21/489-1618-L28

straight  
160×160×51mm

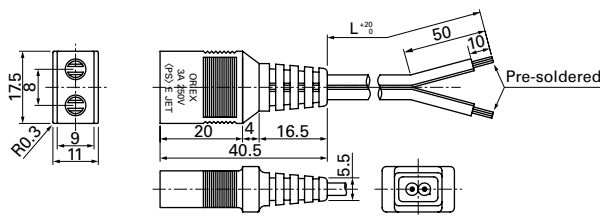

Model No. : 489-1619-L10/489-1619-L21

L-shaped  
φ172mm×51mm  
160×160×51mm

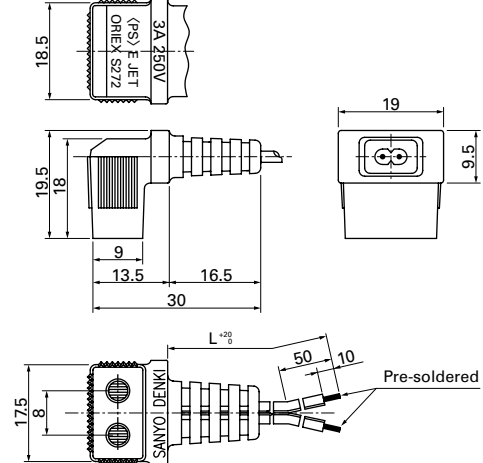

Power cord length

Model	Power cord length(mm)
- L10	1,000
- L21	2,100
- L28	2,800
- L35	3,500


●Be careful when removing the plug/cord out of the package.

**Plug cord**

**UL/CSA CERTIFIED(Unit : mm)**


**Model No. : 489-007-L10/489-007-L21**

UL FILE No.E50197 CSA FILE No.LR67048  
For 120×120×38mm

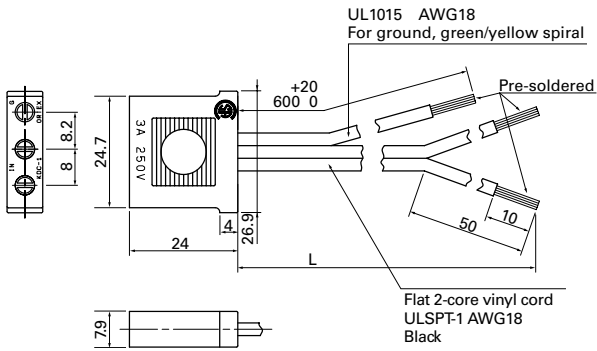


**Model No. : 489-047-L10/489-047-L21**

UL FILE No.E50197 CSA FILE No.LR67048  
For 120×120×25mm  
92×92×25mm  
80×80×25mm  
80×80×38mm

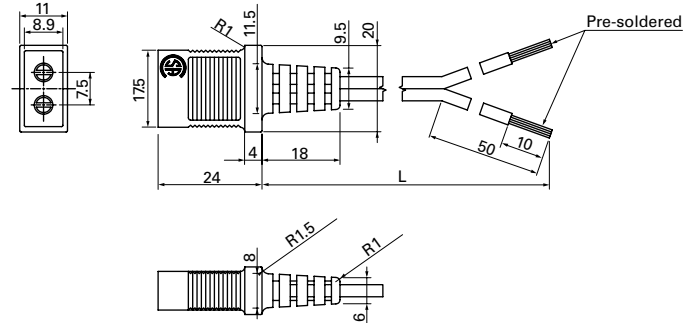


**Model No. : 489-084-L10/489-084-L21**

UL FILE No.E50197 CSA FILE No.LR67048  
L-shaped  
For φ172mm×51mm  
160×160×51mm

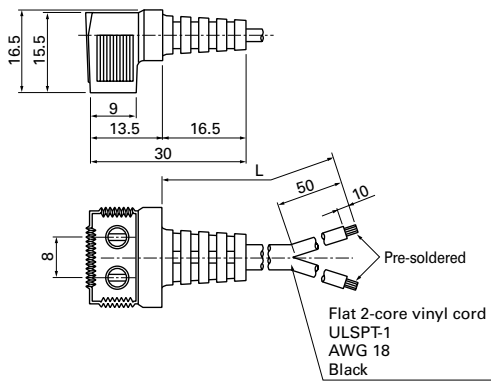

**Model No. : 489-086-L10/489-086-L21**

UL FILE No.E50197 CSA FILE No.LR67048  
straight  
For 160×160×51mm

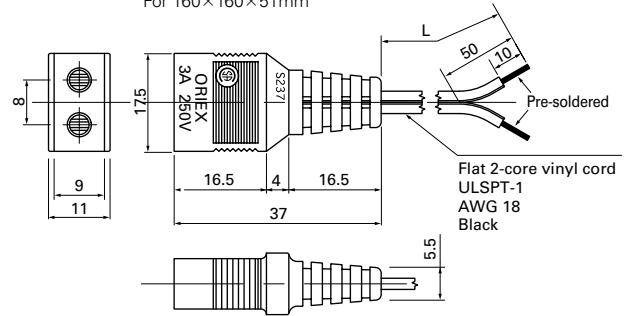

**Power cord length**

Model	Power cord length(mm)
- L10	1,000
- L21	2,100

●Be careful when removing the plug/cord out of the package.