



Brand of NTN corporation

Technical data

UKP.315H

Bearing units




Grey cast housing, radial insert ball bearing with adapter sleeve, seal with slinger

KIT CONTENT

UK315G2H, P315

VISUAL (S)

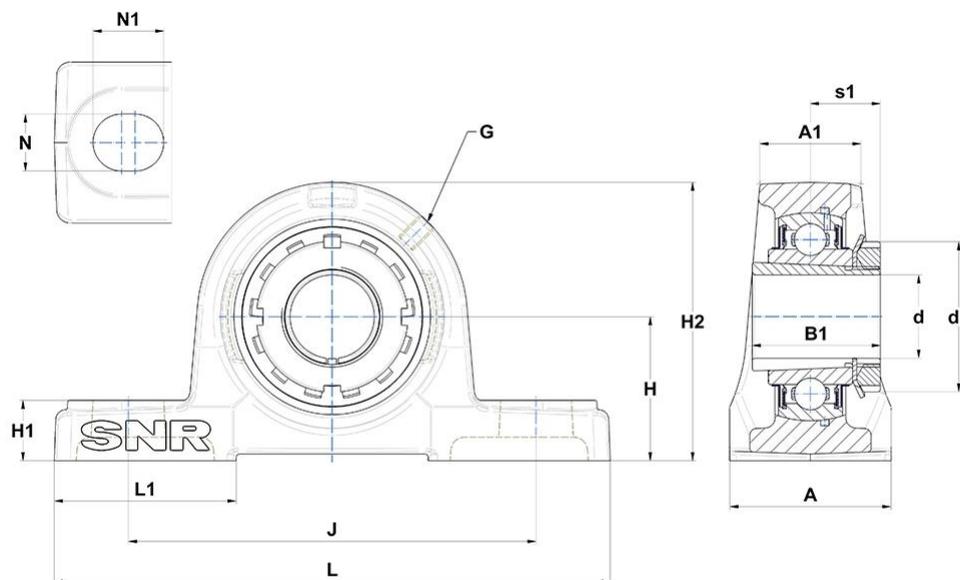

PRODUCT DEFINITION

Brand	SNR
A - Housing width	100 mm
A1 - Housing top width	63 mm
B - Width of Inner Ring	55 mm
d - Shaft diameter	65 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	98 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G - Grease fitting	M10x1
H - Distance mounting base to centerline spheric. seating diam.	100 mm
H1 - Housing foot height	35 mm
H2 - Housing height	198 mm
J - Mounting holes distance	290 mm
L - Housing length	380 mm
L1 - Housing foot length	110 mm
N - Mounting hole dimension	27 mm
N1 - Mounting hole length	40 mm
s1 - Distance nut to middle of bearing raceway	42,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	113360000 mN
C0 - Static load rating	76800000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	14,81 kg
Adapter sleeve designation	H2315

