


Interface module - FLKM 50/DO326/S7-300 - 2321965

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

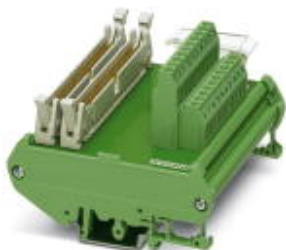

VARIOFACE interface module for failsafe 6ES7 326-2BF01-0AB0 module of the SIMATIC® S7-300 (two 50-pos. FLK connectors), module width: 90 mm

Key commercial data

Packing unit	1
GTIN	 4 046356 428415
Custom tariff number	85369010

Technical data

General

Status display	No
----------------	----

Connection data for connection 1

Connection name	Field level
Connection method	Screw connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12

Connection data for connection 2

Connection name	Controller level
Number of connections	2
Connection method	IDC/FLK pin strip (2.54 mm)
Number of positions	50

Supported controller

Controller	SIEMENS S7-300 / ET 200 M
- suitable I/O card	6ES7 326-2BF01-0AB0
	6ES7 326-2BF10-0AB0

Interface module - FLKM 50/DO326/S7-300 - 2321965

Classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 7.0	27141152

ETIM

ETIM 2.0	EC001434
ETIM 3.0	EC001604
ETIM 4.0	EC001604
ETIM 5.0	EC002780

UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421