

RJI RJ45 jack 1Gbit angl. LV biLEDs LV

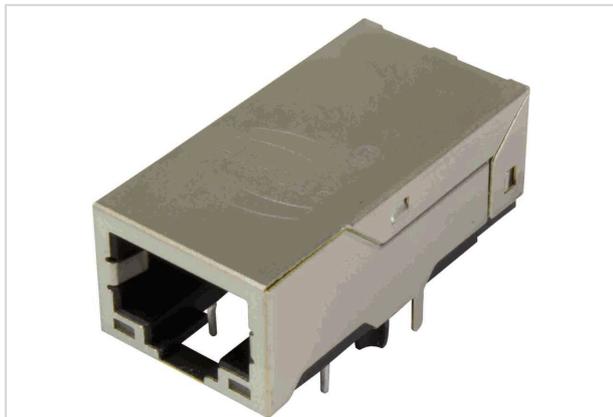


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 551 1542
Specification	RJI RJ45 jack 1Gbit angl. LV biLEDs LV
HARTING eCatalogue	https://harting.com/09455511542

Identification

Category	Connectors
Series	HARTING RJ Industrial® RJ45
Identification	Magnetics
Element	Female
Specification	with integrated transformer Angled With bicolour LED

Version

Termination method	Reflow soldering termination (THR)
Shielding	Fully shielded, 360° shielding contact
Number of contacts	8

Technical characteristics

Rated voltage	30 V
Data rate	10 Mbit/s 100 Mbit/s 1 Gbit/s
Limiting temperature	-40 ... +85 °C
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20

Material properties

RoHS	compliant
------	-----------



Pushing Performance
Since 1945

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

UL / CSA	UL 1977 DUXR2.E254191 CSA-C22.2 No. 182.4, No. 233-09 DUXR8.E254191
Approvals	DNV GL

Commercial data

Packaging size	40
Net weight	9.76 g
Country of origin	China
European customs tariff number	85366990
GTIN	5713140224544
eCl@ss	27460201 PCB connector (board connector)
ETIM	EC002637
UNSPSC 24.0	39121415