


PREVOS1 SAFETY QUICK COUPLINGS - CSI 06

Female thread one port wall bracket
- 1 coupler and drain - ISO 6150 C
Profile



Part number	Female thread	Min. operating pressure (bar)	Flow rate at 6.00 bar (l/min) ($\Delta P = 0.60$ bar)	ID passage (mm)	Temperature min/max (°C)
CSI 061103WK	G1/2	2.00 / 12.00	833.00	6 mm	-15.00 / 70.00

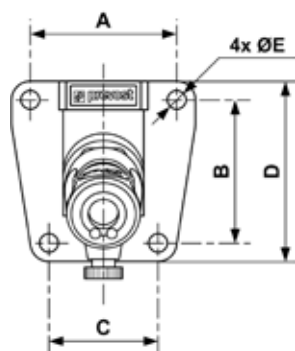

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)	Dim. D (mm)	Dim. E (mm)
CSI 061103WK	51.00	50.00	38.00	63.00	6.50