


PRODUCT-DETAILS

## AMD11844-MG

AMD11844-MG Blind control switch 16AX,  
Double rocker size - MG

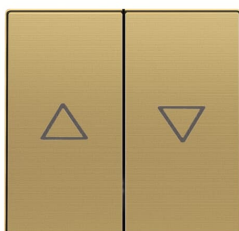

### General Information

Extended Product Type	AMD11844-MG
Product ID	2CLA624410N1701
EAN	8427238099613
Catalog Description	AMD11844-MG Blind control switch 16AX, Double rocker size - MG
Long Description	Rated voltage: 250Vac Rated power: 16AX Output: 2 normally open contact Multi-way input terminal (up/down)

### Ordering

EAN	8427238099613
Customs Tariff Number	85365080
Minimum Order Quantity	10 piece

### Dimensions

Product Net Depth / Length	0.122 m
Product Net Height	0.091 m
Product Net Width	0.116 m
Product Net Weight	0.053 kg

---

## Container Information

---

Package Level 1 Units	10 piece
Package Level 1 EAN	8427238099613
Package Level 1 Depth / Length	0.122 m
Package Level 1 Height	0.091 m
Package Level 1 Width	0.116 m
Package Level 1 Gross Weight	0.53 kg

---



---

## Technical

---

Ambient Air Temperature	Operation -5 ... +35 °C Storage -5 ... +50 °C
Degree of Protection	IP20
Mounting Type	Flush mounted (plaster)

---



---

## Certificates and Declarations (Document Number)

---

Data Sheet, Technical Information	9AKK106930A7740
Declaration of Conformity - CE	No declaration needed
Instructions and Manuals	9AKK106930A7740

---



---

## Classifications

---

ETIM 7	EC000044 - Venetian blind switch/-push button
ETIM 8	EC000044 - Venetian blind switch/-push button
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)

---



---

## Categories

---

Low Voltage Products and Systems → Switch Assortments → Blind & Venetian Control → Mechanical Blind / Venetian - Switch → Mechanical Blind / Venetian - Switch - Flush Mounted → Mechanical Blind / Venetian - Switch

Low Voltage Products and Systems → Switch Assortments → Flush Mounted Range BS - Niessen → Design Millenium → Flush Mounted Inserts with Cover Plate → Mechanical Blind / Venetian - Switch

