


NATR15-PP

Galet de roulement

Yoke type track rollers NATR...-PP-A, single row needle roller bearings with particularly thick-walled outer ring, needle roller and cage assembly and an inner ring, axial guidance of outer ring is provided by the plastic axial plain washers and contact washers, three-stage sealing by plastic axial plain washer on both sides

Information technique

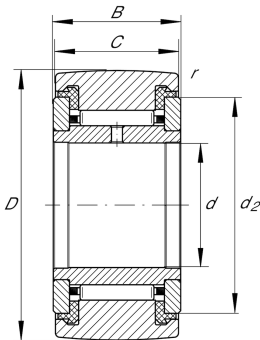

Votre alternative produit actuelle

joint	PP	Joint frottant des deux côtés
profile bague extérieure	IOP	Optimized INA-profile
dispositif de lubrification	IR	Via inner ring

dimensions principale & données de performance

d	15 mm	Alésage
D	35 mm	Diamètre extérieur
B	19 mm	Largeur, bague intérieure
C _{r w}	9.700 N	Charge dyn. de base, radiale
C _{0r w}	14.500 N	Charge stat. de base, radiale
C _{ur w}	1.860 N	Limite à la fatigue, radiale
n _{D G}	3.600 1/min	Vitesse pour une lubrification à la graisse
F _{0r per}	14.500 N	Charge radiale statique admissible
F _{r per}	14.500 N	Charge radial dynamique admissible sur bague extérieure
≈m	0,095 kg	Poids

Dimensions

C	18 mm	Largeur, bague extérieure
d ₂	27,6 mm	Diamètre extérieur rondelle de butée
r _{min}	0,6 mm	Dimension minimum de chanfrein



Caractéristiques



Effort radial



Lubrification à vie, sans entretien



Lubrification à la graisse



Étanche des 2 côtés