


DATASHEET

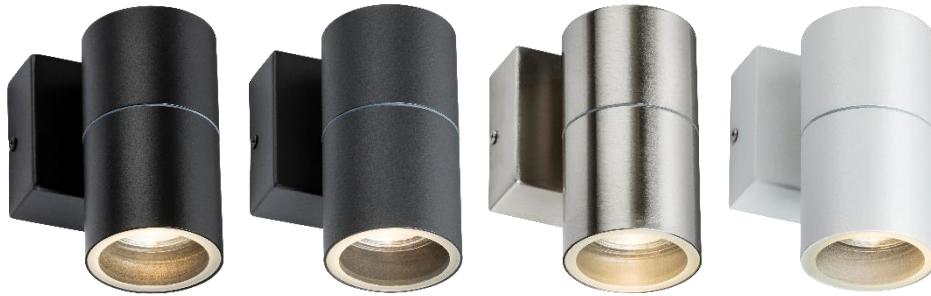

OWALL1xx
230V IP54 GU10
Single Wall Light

www.mlaccessories.co.uk

MLA PART CODE	OWALL1BK	OWALL1A	OWALL1BC	OWALL1W
DESCRIPTION	230V IP54 GU10 Single Wall Light			
FINISH	Black	Anthracite	Brushed Chrome	White
NETT WEIGHT (KG)	0.52			
DIMENSIONS (MM)	Body Diameter – 60 Body Height - 110 Base Height – 71 Base Width - 81 Projection – 96			
MAX WATTAGE (W)	20			
LAMP BASE	GU10			
LAMP TYPE	Halogen / LED Compatible			
INPUT VOLTAGE	Mains 230V 50Hz			
CONSTRUCTION	Stainless Steel			
CLASS	Class I			
IP RATING	IP54			
DIMMABLE	Dependent on lamp			
WARRANTY	2 Years			
ORIGIN OF MANUFACTURE	China			
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes			
MANUFACTURED IN ACCORDANCE WITH	BS EN 60598			
EAN	5056270818512	5056270818604	5056270818611	5056270818628



AKOCT20_V1