

Datasheet

EAS120 Series

120W External Power Supply

784-0603




Features:

- 120W external power supply
- Protections: Short circuit/ Overload/ Over voltage/ Over Temperature
- Input voltage range: 100 to 240VAC
- Fully enclosed plastic case
- Efficiency: Up to 90%
- ErP step2 compliant (level V)


Model		
Output	DC Voltage	48V
	Rated current	2.5A
	Current range	0-2.5A
	Rated Power	120W
Input	Voltage range	100-240VAC
	Frequency range	47-63Hz
	Efficiency	Up to 90%
Protections	Short circuit	Auto recovery
Environment	Working temperature	0°C - 40°C
Other	Weight	540.4g
	Dimensions	167*67*35mm (L*W*H)
Connector	Plug	2.5mm

Standard plug(For 20V,24V,48V only)


P1M	
P/N	OUTPUT
CENTER	+

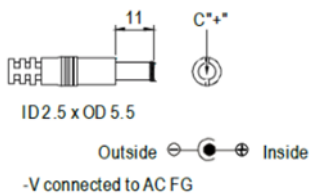

Derating Curve

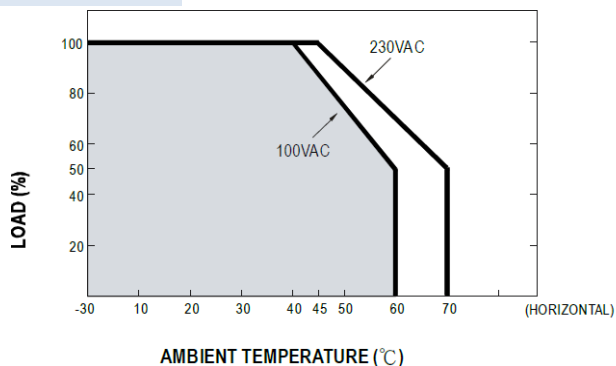

Static Characteristics

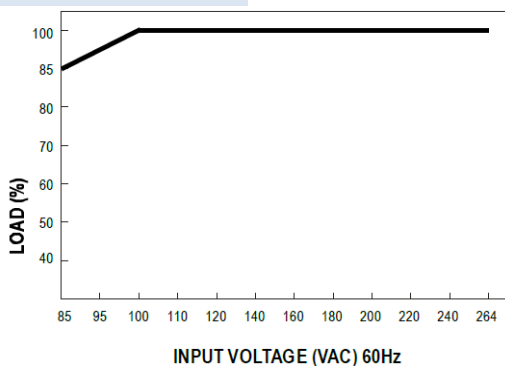

Mechanical Specification

