

DIMMABLE DOWNLIGHT CIO


4126261

16 W - 1500lm - 4000K

IP20

50.000 H

 DIMMABLE

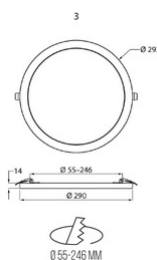

DIMENSIONS	A	B	C
1	14	---	290

GENERAL INFORMATIONS	
Code	4126261
Ean	6435200242020
Family	DIMMABLE DOWNLIGHT CIO
Technology	LED
Operating temperature (° C)	0 - +35

PACKAGING	
Packaging	BOX
Pack	10

LIGHTING DATA	
Kelvin (°)	4000
Lumen	1500
Beam (°)	100
Luminous efficacy (lm / W)	93,75

TECHNICAL FEATURES	
Power (W)	16
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50
Hole diameter (mm)	246
Insulation class	2
Dimmer compatibility	SI

DIMMABLE DOWNLIGHT CIO

4126261

16W - 1500lm - 4000K

- Panel with side light source and driver incorporated in the frame, total thickness 14mm
- Surface mounted with quick release mounting bracket
- Recessed with adjustable mounting bracket for Ø55-246mm hole (depending on model)
- Dimmable (TRIAC)