

FEATURES

- Single row tapered roller bearing
- Accommodates combined radial and axial loads
- Low frictional moments during operation
- Seperable rings
- Pressed steel cage

Tapered Roller Bearing 25x62x18.25mm

RS Stock No.: 2482794




RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

A range of RS Pro single row Tapered Roller Bearings, offering versatility and overall high performance. RS Pro Tapered Roller bearings utilise a high strength steel cage and optimised internal geometry to ensure adequate operation.

General Specifications

Bearing Type	Single Row Tapered Roller Bearing
Number of Rows	1
Material	Steel
Race Type	Tapered
Bore Type	Cylindrical
Application	Pumps, Gearboxes, Motors
Material of cage	Pressed steel

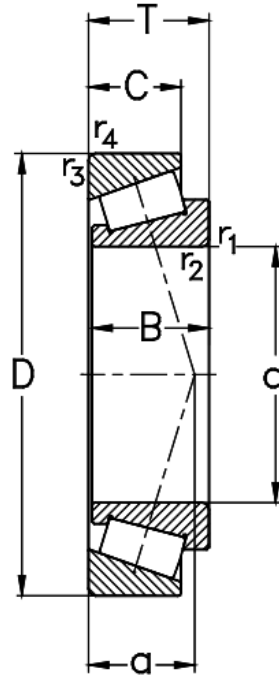

Mechanical Specifications

Inside Diameter (d)	25mm
Outside Diameter (D)	62mm
Cone Width (B)	17mm
Cup Width (C)	13mm
Assembled Width (T)	18.25mm
Dynamic Load Rating	37.5kN
Static Load Rating	39kN
Limiting Speed	11000rpm
Mass	0.28kg

Operation Environment Specifications

Temperature Range	-15°C to 120°C
-------------------	----------------

INCLUDES WITH PRODUCT / STANDARD ACCESSORIES /
CONSTRUCTIONAL DIAGRAM