

PARATHOM CL P 40 ADV 6 W/827 E27 CS

PARATHOM CLASSIC P advanced | Dimmable LED lamps, classic mini-ball shape, with retrofit screw base



Areas of application

- General illumination
- Domestic applications

Product benefits

- Very low energy consumption
- Extremely long life
- Robust against vibrations
- No UV and near-IR radiation in the light beam
- Instant 100 % light, no warm-up time
- Simple direct replacement for conventional incandescent lamps
- Lower thermal output (compared with the standard reference product)
- Correct operation even at low temperatures

Product features

- Professional LED lamps for line voltage
- Dimmable (with many common dimmers, see also www.osram.com/dim)
- Available with E14 or E27 screw base
- Lifetime: up to 25,000 h
- Mercury-free lamps



Technical data


Electrical data

Rated wattage	6 W
Nominal wattage	6 W
Nominal voltage	220...240 V
Operating frequency	50...60 Hz
Power factor λ	0.55
Claimed equiv. conventional lamp power	40 W
Energy consumption	6 kWh/1000h

Light technical data

Nominal luminous flux	470 lm
Rated luminous flux	470 lm
Color temperature	2700 K
Color rendering index Ra	80
Warm-up time (60 %)	0.00 s
Lumen main.fact.at end of nom.life time	0.70
Light color as per EN 12464-1	Warm White
Starting time	< 0.5 s
Standard deviation of color matching	≤ 6 sdc _m
Lumen maintenance at end of service life	0.70

Dimensions & weight

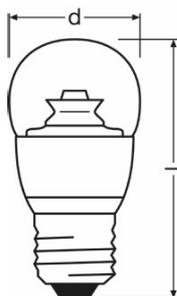

Product line drawing

Overall length	89.0 mm
Diameter	43.0 mm

Product datasheet

Outer bulb	P40
Length	89.0 mm


Colors & materials

Mercury-free	Yes
--------------	-----

Lifespan

Nominal lamp life time	20000 h
Rated lamp life time	20000 h
Number of switching cycles	100000

Additional product data

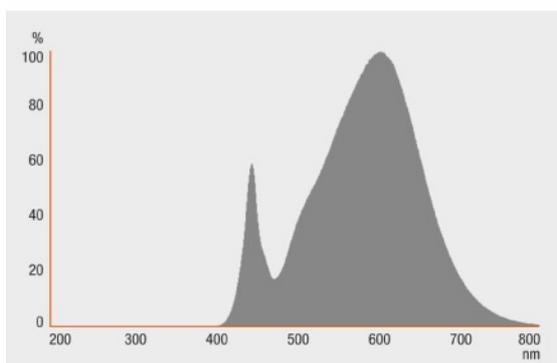

Spectral power distribution

Base (standard designation)	E27
New article	NEW
Design / version	Clear
Appropriate disposal acc. to WEEE	Yes
Footnote used only for product	All technical parameters apply to the entire lamp/Due to the complex production process for light-emitting diodes, the typical values shown for the technical LED parameters are purely statistical values that do not necessarily match the actual technical parameters of each individual product, which can vary from the typical value/In preparation

Product datasheet

Capabilities

Dimmable	Yes ¹⁾
-----------------	-------------------

¹⁾ With many common dimmers

Certificates & standards

Energy efficiency class	A+
--------------------------------	----

Country specific categorizations

ILCOS	DRBP/C-6,2-220-240-E27-43/89
--------------	------------------------------

Country specific information

Product code	METEL-Code	SEG number	STK-Number	UK Org
4052899911475	-	8334296	-	-

Product datasheet



Guarantee

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4052899911475	PARATHOM CL P 40 ADV 6 W/827 E27 CS	Folding carton box 1	95 mm x 45 mm x 44 mm	0.19 dm ³	85.00 g
4052899911550	PARATHOM CL P 40 ADV 6 W/827 E27 CS	Shipping carton box 10	- x - x -		
4052899040649	PARATHOM CL P 40 ADV 6 W/827 E27 CS	Shipping carton box 60	- x - x -		

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

For dimming conformity see

▶ www.osram.com/DIM

For further products and actual information concerning LED lamps see

▶ www.osram.com/ledlamps

For Guarantee see

▶ www.osram.com/guarantee

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.