


PREVOST FILTRATION - KOMBINATIONEN VON EINHEITEN

Doppelblock - Filterregler mit Öler
und Sicherheitskupplung prevo S1

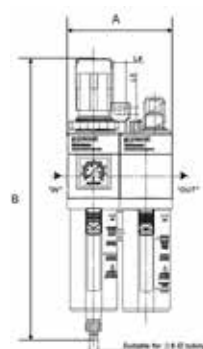

Max. Betriebsdruck
10 bar

Filterung (µm)
25.00
25

Min/Max Temperatur
5 / 50 °C

Art. Nr	IG		Profil	Nettogewicht (Kg)
ATU B2585102ES	G3/8	2 / 8.5	EUROPEAN	2.2
ATU B2585103ES	G1/2	2 / 8.5	EUROPEAN	2.2
ATU B2585102CS	G3/8	2 / 8.5	ISO 6150C	2.2
ATU B2585103CS	G1/2	2 / 8.5	ISO 6150C	2.2
ATU B2585102AS	G3/8		ARO 210	2.2
ATU B2585103AS	G1/2			2.2